

SNA Terminal Blocks
T&B Catalog Number:

011564622

UPC Number:

66201995743

Status:

Active

Description:

Beige, fuse holder terminal blocks, double-deck for 5 x 20 and 5 x 25 mm fuses with 8 mm spacing, 26 Amp rated UL current that accepts 12 AWG UL wire

Features

Includes IP20 protection

Application

For use with applications ranging from standard distribution and control panels, to specialized applications in key industries such as traction, energy, maritime, explosive atmospheres, material handling, etc.

General

Style Fuse Holder

Color Beige

Mounting DIN 1-3

Series M4/8.D2.SF.V0

Connection Technology Screw Clamp

UL Wire Range (AWG) 24-12

Rated IEC Wire Range (Solid) (mm²) 4

Dimension Information

L x W x H (mm) 85.7 x 71.5

Spacing (mm) 8

L x W x H (in) 3.37 x 2.81

Spacing (inches) 0.315

Specifications

UL Current (Amps) 20

UL Voltage (VAC) 300

Rated UL Wire Size (AWG) 12

IEC Voltage (VAC) 630

IEC Current (Amps) 6.3

Packaging

T&B Order Multiple 50

T&B Inner Pack 50

Package in Units 450

T&B Sold in UOM Each

T&B Weight Per UOM 6.5 lbs. per 100

Certifications


Approvals IEC, UL/CSA

For further technical assistance, please contact us...

Thomas & Betts - USA
 8155 T&B Blvd.
 Memphis, TN 38125
 www.tnb.com

T&B Technical Support
 MS 3B-50
 8155 T&B Blvd.
 Memphis, TN 38125

Hours: 7AM - 6PM CDT
 Monday-Friday
 Phone: (888) 862-3289
 Fax: (901) 252-1321
 Email:techsupport@tnb.com

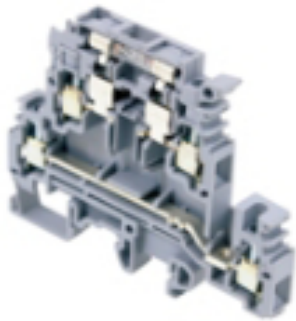

SNA Terminal Blocks
T&B Catalog Number:

011564622

UPC Number:

66201995743

Status:

Active

Description:

Beige, fuse holder terminal blocks, double-deck for 5 x 20 and 5 x 25 mm fuses with 8 mm spacing, 26 Amp rated UL current that accepts 12 AWG UL wire

Features

Includes IP20 protection

Application

For use with applications ranging from standard distribution and control panels, to specialized applications in key industries such as traction, energy, maritime, explosive atmospheres, material handling, etc.

General

Style	Fuse Holder
Color	Beige
Mounting	DIN 1-3
Series	M4/8.D2.SF.V0
Connection Technology	Screw Clamp
UL Wire Range (AWG)	24-12
Rated IEC Wire Range (Solid) (mm ²)	4

Dimension Information

L x W x H (mm)	85.7 x 71.5
Spacing (mm)	8
L x W x H (in)	3.37 x 2.81
Spacing (inches)	0.315

Specifications

UL Current (Amps)	20
UL Voltage (VAC)	300
Rated UL Wire Size (AWG)	12
IEC Voltage (VAC)	630
IEC Current (Amps)	6.3

Packaging

T&B Order Multiple	50
T&B Inner Pack	50
Package in Units	450
T&B Sold in UOM	Each
T&B Weight Per UOM	6.5 lbs. per 100

Certifications

Approvals	IEC, UL/CSA
-----------	-------------

For further technical assistance, please contact us...

Thomas & Betts - USA
 8155 T&B Blvd.
 Memphis, TN 38125
 www.tnb.com

T&B Technical Support
 MS 3B-50
 8155 T&B Blvd.
 Memphis, TN 38125

Hours: 7AM - 6PM CDT
 Monday-Friday
 Phone: (888) 862-3289
 Fax: (901) 252-1321
 Email:techsupport@tnb.com