



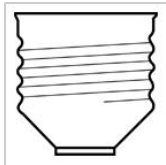

GE
Lighting

12658 - 15A15

GE A15

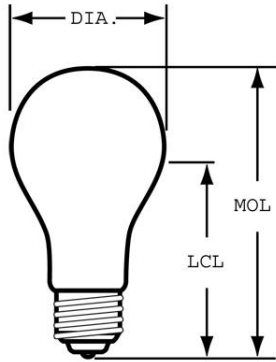

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	A15
Base	Medium Screw (E26)
Filament	C-9
Bulb Finish	Inside frost
Rated Life	2500.0 hrs
Bulb Material	Soft glass
Primary Application	Ceiling Fan

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	115.0
Nominal Initial Lumens per Watt	7

ELECTRICAL CHARACTERISTICS

Wattage	15.0
Voltage	130.0

DIMENSIONS

Maximum Overall Length (MOL)	3.5000 in(88.9 mm)
Bulb Diameter (DIA)	1.875 in(47.6 mm)
Light Center Length (LCL)	2.370 in(60.2 mm)

PRODUCT INFORMATION



Product Code	12658
Description	15A15
Standard Package	Case
Standard Package GTIN	00043168126588
Standard Package Quantity	120
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	120
UPC	043168909839



GE
Lighting

12658 - 15A15

GE A15

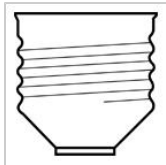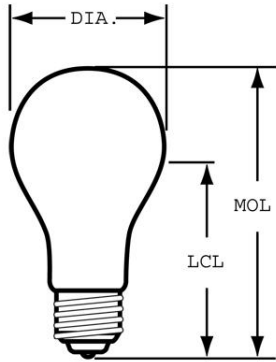

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	A15
Base	Medium Screw (E26)
Filament	C-9
Bulb Finish	Inside frost
Rated Life	2500.0 hrs
Bulb Material	Soft glass
Primary Application	Ceiling Fan

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	115.0
Nominal Initial Lumens per Watt	7

ELECTRICAL CHARACTERISTICS

Wattage	15.0
Voltage	130.0

DIMENSIONS

Maximum Overall Length (MOL)	3.5000 in(88.9 mm)
Bulb Diameter (DIA)	1.875 in(47.6 mm)
Light Center Length (LCL)	2.370 in(60.2 mm)

PRODUCT INFORMATION

Product Code	12658
Description	15A15
Standard Package	Case
Standard Package GTIN	00043168126588
Standard Package Quantity	120
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	120
UPC	043168909839