







GE
Lighting

13390 - 15T6

GE appliance 15 watt T6 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's Indicator Lights are designed for home appliances and many small fixtures requiring a candleabra base.
- 120 volts
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens
- Lasts 2000 hours
- T6 shape with candelabra base for use in appliances

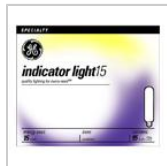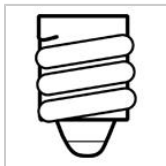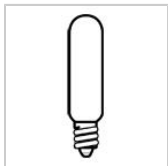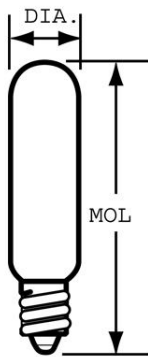

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Tubular
Bulb	T6
Base	Candelabra Screw (E12)
Filament	C-7A
Bulb Finish	Clear
Rated Life	2000.0 hrs
Bulb Material	Soft glass
Primary Application	Appliance;Standard;Standard

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	107.0
Nominal Initial Lumens per Watt	7

ELECTRICAL CHARACTERISTICS

Wattage	15.0
Voltage	120.0

DIMENSIONS

Maximum Overall Length (MOL)	3.0600 in(77.7 mm)
Bulb Diameter (DIA)	0.750 in(19.0 mm)
Light Center Length (LCL)	1.560 in(39.6 mm)

PRODUCT INFORMATION

Product Code	13390
Description	15T6
Standard Package	Case
Standard Package GTIN	10043168133903
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard	60
Package	
UPC	043168133906







GE
Lighting

13390 - 15T6

GE appliance 15 watt T6 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's Indicator Lights are designed for home appliances and many small fixtures requiring a candleabra base.
- 120 volts
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens
- Lasts 2000 hours
- T6 shape with candelabra base for use in appliances

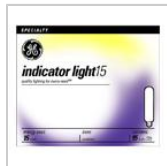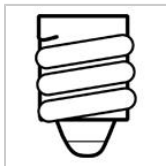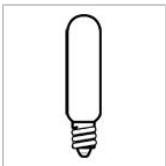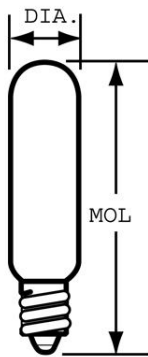

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Tubular
Bulb	T6
Base	Candelabra Screw (E12)
Filament	C-7A
Bulb Finish	Clear
Rated Life	2000.0 hrs
Bulb Material	Soft glass
Primary Application	Appliance;Standard;Standard

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	107.0
Nominal Initial Lumens per Watt	7

ELECTRICAL CHARACTERISTICS

Wattage	15.0
Voltage	120.0

DIMENSIONS

Maximum Overall Length (MOL)	3.0600 in(77.7 mm)
Bulb Diameter (DIA)	0.750 in(19.0 mm)
Light Center Length (LCL)	1.560 in(39.6 mm)

PRODUCT INFORMATION

Product Code	13390
Description	15T6
Standard Package	Case
Standard Package GTIN	10043168133903
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard	60
Package	
UPC	043168133906