



 


GE  
Lighting

### 34272 - 20T61/2/F

GE appliance 20 watt T6.5 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's Appliance Lights can be used in many household appliances such as microwaves, refrigerators and ovens.
- 120 volts
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens
- Lasts 7000 hours
- T6.5 shape with intermediate base for use in appliances

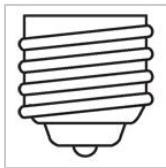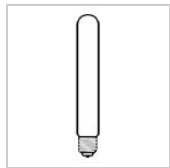

#### GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Tubular
Bulb	T6.5
Base	Intermediate Screw (E17)
Filament	C-8
Bulb Finish	Frost
Rated Life	7000.0 hrs
Bulb Material	Soft glass
Primary Application	Exit
	Sign;Appliance;Standard;Standard

#### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	90.0
Nominal Initial Lumens per Watt	4

#### ELECTRICAL CHARACTERISTICS

Wattage	20.0
Voltage	120.0

#### DIMENSIONS

Maximum Overall Length (MOL)	5.5000 in(139.7 mm)
Bulb Diameter (DIA)	0.813 in(20.7 mm)

#### PRODUCT INFORMATION

Product Code	34272
Description	20T61/2/F
Standard Package	Case
Standard Package GTIN	00043168342728
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	60
UPC	043168910217


 


GE  
Lighting

### 34272 - 20T61/2/F

GE appliance 20 watt T6.5 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's Appliance Lights can be used in many household appliances such as microwaves, refrigerators and ovens.
- 120 volts
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens
- Lasts 7000 hours
- T6.5 shape with intermediate base for use in appliances

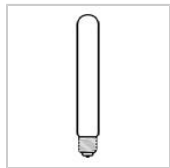

#### GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Tubular
Bulb	T6.5
Base	Intermediate Screw (E17)
Filament	C-8
Bulb Finish	Frost
Rated Life	7000.0 hrs
Bulb Material	Soft glass
Primary Application	Exit Sign;Appliance;Standard;Standard

#### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	90.0
Nominal Initial Lumens per Watt	4

#### ELECTRICAL CHARACTERISTICS

Wattage	20.0
Voltage	120.0

#### DIMENSIONS

Maximum Overall Length (MOL)	5.5000 in(139.7 mm)
Bulb Diameter (DIA)	0.813 in(20.7 mm)

#### PRODUCT INFORMATION

Product Code	34272
Description	20T61/2/F
Standard Package	Case
Standard Package GTIN	00043168342728
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	60
UPC	043168910217