


## Connectors - Zinc

### Images

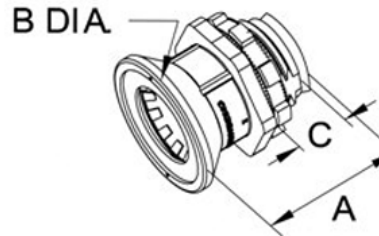

### Application

The 251-MBI is used to connect a properly deburred length of EMT raceway to a box device, panelboard, or similar electrical enclosure. Simply push the fitting onto raceway with a slight twist. Remove the fitting by unthreading it from conduit end. No tools are required. Concrete Tight. Patented

### Product Information

[Download Photo Image](#)    [Download Dimensional Image](#)  
Dimension A in Inches: 1.47  
Dimension B in Inches: 1.50  
Dimension C in Inches: .46

Material: Zinc Alloy body and locknut with steel internal components  
Finish: Mirror finish/Ball Burnish

### Certifications & Codes:

CSA File Number: C22.2 18.3-04  
Federal Specification Number: A-A-50553  
NEMA Standard: FB-1  
UL File Number: E24001,cULus  
UL Standard: 514B  
UNSPSC: 39121434

**Catalog ID:** 251-MBI

**UPC Number:** 78174724251

**Description:** The Mighty-Bite™ 251-MB is a PUSH-EMT® Insulated Throat Connector.

**Application:** The 251-MBI is used to connect a properly deburred length of EMT raceway to a box device, panelboard, or similar electrical enclosure. Simply push the fitting onto raceway with a slight twist. Remove the fitting by unthreading it from conduit end. No tools are required. Concrete Tight. Patented

**Trade Size:** 3/4"

**Country of Manufacture:** USA

**Std Pkg Qty:** 250

**Unit Qty:** 25