


Connectors - Raintight

Images

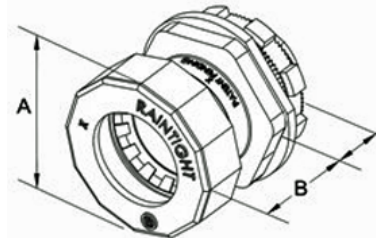

Application

The 251-MSRT installation is accomplished by inserting a properly deburred end of EMT into the end of the Mighty-Seal® and slightly rotating the UL listed fitting until the conduit reaches the end stop. Removal is accomplished by loosening the nut and removing the component parts from the end of the conduit. Reassemble the fitting in the reverse order of the removal process and re-use. Patented

Product Information

[Download Photo Image](#) [Download Dimensional Image](#)
Dimension A in Inches: 1.47
Dimension B in Inches: 1.12
Dimension C in Inches: .50

Material: Zinc Die Cast
Finish: Ball Burnished

Certifications & Codes:

Federal Specification Number:	A-A-505553
NEMA Standard:	FB-1
UL File Number:	UL514B & CSA 22.2
UL Standard:	E24001,cULus
UNSPSC:	39121434
Patent Number:	7,841,630; 8,474,877

Catalog ID: 251-MSRT

UPC Number: 78174717251

Description: Bridgeport Fittings Mighty-Seal® 3/4 inch EMT Connectors are used to connect a 3/4 inch EMT raceway to a box, device or enclosure. The 251MSRT 3/4 inch Mighty-Seal® connector is UL listed for use in wet locations. Raintight. Patented

Application: The 251-MSRT installation is accomplished by inserting a properly deburred end of EMT into the end of the Mighty-Seal® and slightly rotating the UL listed fitting until the conduit reaches the end stop. Removal is accomplished by loosening the nut and removing the component parts from the end of the conduit. Reassemble the fitting in the reverse order of the removal process and re-use. Patented

Trade Size: 3/4"

Country of Manufacture: USA

Std Pkg Qty: 250

Unit Qty: 25