
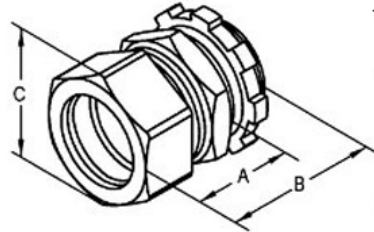


Connectors - Zinc

Images

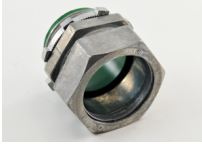

Application

Used to join steel EMT to box or enclosure. Concrete-tight. 1/2" thru 2" suitable for use with Steel or Aluminum EMT. Insulator rated 105°C. CSA Listed Raintight/For Use in Wet Locations in Canada Only

Product Information

Material: Zinc Die Cast
Finish: Ball burnished, mirror smooth

Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50553
NEMA Standard:	FB-1
UL File Number:	E24001
UL Standard:	UL-514B
UNSPSC:	39121434

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 5/8
Dimension B in Inches: 1-3/16
Dimension C in Inches: 2-1/8

Catalog ID: 253-DC12

UPC Number: 781747162533

Description: Connector, Compression, Zinc Die Cast, 105°C Insulated Throat, Size 1 1/4 Inch

Application: Used to join steel EMT to box or enclosure. Concrete-tight. 1/2" thru 2" suitable for use with Steel or Aluminum EMT. Insulator rated 105°C. CSA Listed Raintight/For Use in Wet Locations in Canada Only

Trade Size: 1-1/4"

Country of Manufacture: USA

Std Pkg Qty: 100

Unit Qty: 10