
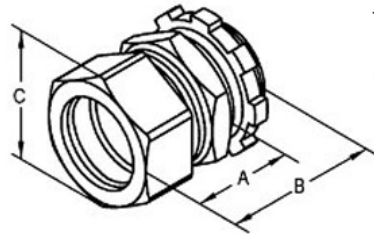


Connectors - Zinc

Images

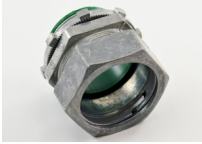

Application

Used to join steel EMT to box or enclosure. Concrete-tight. 1/2" thru 2" suitable for use with Steel or Aluminum EMT. Insulator rated 105°C. CSA Listed Raintight/For Use in Wet Locations in Canada Only

Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth

Certifications & Codes:

CSA File Number: LR39354

Federal Specification Number: A-A-50553

NEMA Standard: FB-1

UL File Number: E24001

UL Standard: UL-514B

UNSPSC: 39121434

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 5/8

Dimension B in Inches: 1-5/16

Dimension C in Inches: 2-7/16

Catalog ID: 254-DC12

UPC Number: 781747162540

Description: Connector, Compression, Zinc Die Cast, 105 Degree C Insulated Throat, Size 1 1/2 Inch

Application: Used to join steel EMT to box or enclosure. Concrete-tight. 1/2" thru 2" suitable for use with Steel or Aluminum EMT. Insulator rated 105°C. CSA Listed Raintight/For Use in Wet Locations in Canada Only

Trade Size: 1-1/2"

Country of Manufacture: USA

Std Pkg Qty: 40

Unit Qty: 10