


## Connectors - Zinc - Raintight

### Images

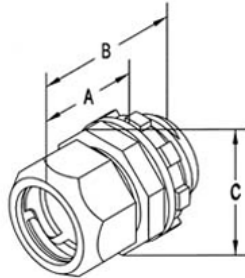

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 3/4

Dimension B in Inches: 1-3/8

Dimension C in Inches: 2-15/16

### Application

Compression style connector with internal sealing ring and knockout gasket to create a raintight seal when connecting EMT to box or enclosure. Insulated Throat - 90° C. Patented

### Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth

### Certifications & Codes:

Federal Specification Number: A-A-50553

NEMA Standard: FB-1

UL File Number: E24001

UL Standard: UL-514B

UNSPSC: 39121434

**Catalog ID:** 255-RTI2

**UPC Number:** 781747192554

**Description:** 2" Raintight Compression Connector, Insulated

**Application:** Compression style connector with internal sealing ring and knockout gasket to create a raintight seal when connecting EMT to box or enclosure. Insulated Throat - 90° C. Patented

**Trade Size:** 2"

**Country of Manufacture:** USA of USA and Imported Parts

**Std Pkg Qty:** 10

**Unit Qty:** ---