

3" Raintight Coupling


With Bridgeport's newly redesigned Raintight Compression Couplings, 266-RT through 269-RT, contractors can install just one wet location fitting

These 2-1/2" thru 4" dual Listed Zinc Alloy fittings come standard with a 105° C temperature rated insulated throat and the words "Rigid / EMT and marking helps the AHJ to precisely confirm the products intended use.

Patented



[Download Photo](#)

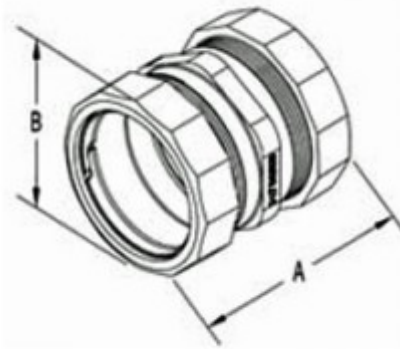

[Download Drawing](#)



[Download Drawing](#)

Product details

Catalog Number:	267-RT
UPC Number:	78174714267
Primary Materials:	Zinc Die Cast
Trade Size:	3"
Standard Package Quantity:	12

Dimensions

Trade Size:	3"
Dimensions A:	4.00
Dimensions B:	4.08

Certifications & Codes

Federal Specification Number: A-A-50553

UL File Number: E24001

UNSPSC: 39131707

Nema Standard: FB-1

UL Standard: UL-514B

Patent Number: 9,787,070; 9,343,883; 7,976,070; 7,604,261; 7,390,027

Country Of Manufacture: USA