

Nothing but **HEAVY DUTY**™

Search MilwaukeeTool.com

NEW PRODUCTS & OFFERS

TOOLS

ACCESSORIES

TEST & MEASUREMENT

HAND TOOLS

PARTS & SERVICE

BUY NOW

Home > Products > Tools > Cordless Tools > Combo Kits > M18™ Cordless LITHIUM-ION 4-Tool Combo Kit

M18™ Cordless LITHIUM-ION 4-Tool Combo Kit

2694-24

PRINT




996



3358



4453

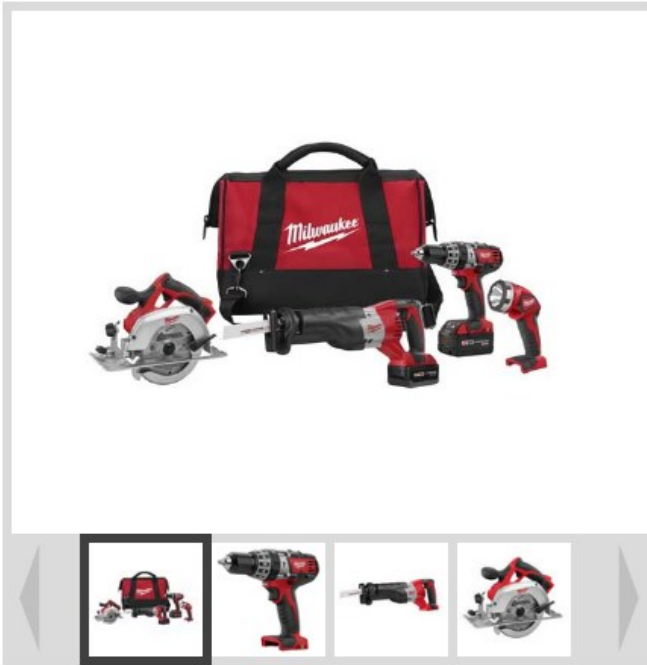Be the first to [Write a Review](#)

The 2694-24 M18 cordless LITHIUM-ION 4-tool combo kit includes the 1/2" Hammer Drill / Driver (2602-20), Sawzall® Recip Saw (2620-20), Circular Saw (2630-20), and Work Light (49-24-0171). The M18™ Cordless LITHIUM-ION System's patented technologies and electronics, innovative motor design, and superior ergonomics provide the most efficient blend of power, weight and performance in the industry. Powered by RED LITHIUM™, the M18™ cordless LITHIUM-ION system delivers more torque, more power, and longer run-time than the competition.

SHOW MORE

Includes

- M18™ 2602-20 1/2" Hammer Drill/Driver
- M18™ 2620-20 SAWZALL® Recip Saw
- M18™ 6-1/2" Circ Saw
- M18™ Work Light
- (2) M18™ XC High Capacity RED LITHIUM™ Batteries
- 1-Hour Charger
- General Purpose SAWZALL® Blade
- Contractor Bag

[FIND RETAILERS](#)

FEATURES

- M18™ Cordless ½" Hammer Drill / Driver with Milwaukee 4-Pole Frameless Motor delivers 525 in-lbs of peak torque, 0-550/0-1,700 RPM, & 29,000 BPM
- M18™ Cordless Sawzall® Reciprocating Saw with Patented Gear-Protecting Clutch and Counter Balance Mechanism
- M18™ Cordless 6-½" Circular Saw Delivers 3,500 RPM with Magnesium Upper and Lower Guards for Maximum Durability
- M18™ Cordless Work Light Provides a Fold-Away Hook for Hands Free Use and a 135-Degree Rotating Head to Direct Light at the Work Area

SPECIFICATIONS

Voltage	18V
Battery	(2) M18™ Cordless XC High Capacity RED LITHIUM™ Batteries
Charger	1-Hour Charger
Number of Tools	4
Carrier	Contractor Bag
Shipping Weight	29.28lbs

RELATED ARTICLES



Milwaukee M18 Cordless 4-Tool Combo 2694-24 Review

RELATED ITEMS



M18™ XC High Capacity
RED LITHIUM™ Battery



M18™ Compact RED
LITHIUM™ Battery



M18™ Cordless
LITHIUM-ION 3/4" High
Torque Impact Wrench
w/Friction Ring Kit

[MORE RELATED ITEMS](#)

Find us on Facebook



Milwaukee Electric Tool



6,396 people like **Milwaukee Electric Tool**.



Robert



José G.



Sean



Derek



Sergio



Dave



Mikael



Scott

Facebook social plugin

Sign Up for the
Heavy Duty Club



SUBMIT ▶

Products

- New Products & Offers
- Tools
- Accessories
- Test & Measurement
- Milwaukee Gear
- Print Current Catalog

Parts & Service

- e-SERVICE Tool Repair
- Test & Measure Service
- Find a Service Center
- Download Manuals
- Parts Pricing
- Milwaukee Warranty
- Lightning Max Repair
- FAQ's

News & Media

- Press Releases
- MilwaukeeCain.com
- Product Reviews
- Media Center
- Media Inquiries

About Us

- Milwaukee Story
- Careers
- Locations
- Buy Now**
- Contact Us

Nothing but **HEAVY DUTY**™

Search Milwaukee.com

NEW PRODUCTS & OFFERS

TOOLS

ACCESSORIES

TEST & MEASUREMENT

HAND TOOLS

PARTS & SERVICE

BUY NOW

Home > Products > Tools > Cordless Tools > Combo Kits > M18™ Cordless LITHIUM-ION 4-Tool Combo Kit

M18™ Cordless LITHIUM-ION 4-Tool Combo Kit

2694-24

PRINT



996




Share

3358



ShareThis

4453

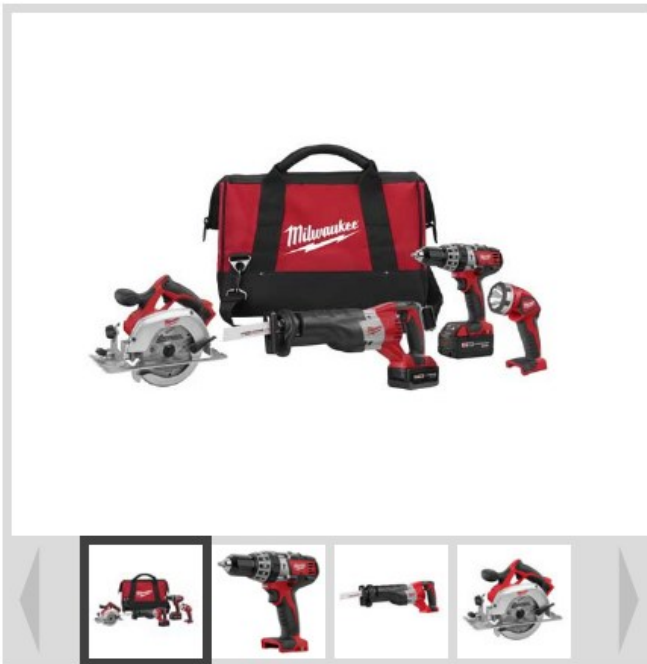

Be the first to Write a Review

The 2694-24 M18 cordless LITHIUM-ION 4-tool combo kit includes the 1/2" Hammer Drill / Driver (2602-20), Sawzall® Recip Saw (2620-20), Circular Saw (2630-20), and Work Light (49-24-0171). The M18™ Cordless LITHIUM-ION System's patented technologies and electronics, innovative motor design, and superior ergonomics provide the most efficient blend of power, weight and performance in the industry. Powered by RED LITHIUM™, the M18™ cordless LITHIUM-ION system delivers more torque, more power, and longer run-time than the competition.

SHOW MORE

Includes

- M18™ 2602-20 1/2" Hammer Drill/Driver
- M18™ 2620-20 SAWZALL® Recip Saw
- M18™ 6-1/2" Circ Saw
- M18™ Work Light
- (2) M18™ XC High Capacity RED LITHIUM™ Batteries
- 1-Hour Charger
- General Purpose SAWZALL® Blade
- Contractor Bag

FIND RETAILERS

FEATURES

- M18™ Cordless 1/2" Hammer Drill / Driver with Milwaukee 4-Pole Frameless Motor delivers 525 in-lbs of peak torque, 0-550/0-1,700 RPM, & 29,000 BPM
- M18™ Cordless Sawzall® Reciprocating Saw with Patented Gear-Protecting Clutch and Counter Balance Mechanism
- M18™ Cordless 6-1/2" Circular Saw Delivers 3,500 RPM with Magnesium Upper and Lower Guards for Maximum Durability
- M18™ Cordless Work Light Provides a Fold-Away Hook for Hands Free Use and a 135-Degree Rotating Head to Direct Light at the Work Area

SPECIFICATIONS

Voltage	18V
Battery	(2) M18™ Cordless XC High Capacity RED LITHIUM™ Batteries
Charger	1-Hour Charger
Number of Tools	4
Carrier	Contractor Bag
Shipping Weight	29.28lbs

RELATED ARTICLES



Milwaukee M18 Cordless 4-Tool Combo 2694-24 Review

RELATED ITEMS



M18™ XC High Capacity
RED LITHIUM™ Battery



M18™ Compact RED
LITHIUM™ Battery



M18™ Cordless
LITHIUM-ION 3/4" High
Torque Impact Wrench
w/Friction Ring Kit

[MORE RELATED ITEMS](#)

Find us on Facebook



Milwaukee Electric Tool



6,396 people like **Milwaukee Electric Tool**.



Robert



José G.



Sean



Derek



Sergio



Dave



Mikael



Scott

Facebook social plugin

Sign Up for the
Heavy Duty Club



SUBMIT ▶

Products

- New Products & Offers
- Tools
- Accessories
- Test & Measurement
- Milwaukee Gear
- Print Current Catalog

Parts & Service

- e-SERVICE Tool Repair
- Test & Measure Service
- Find a Service Center
- Download Manuals
- Parts Pricing
- Milwaukee Warranty
- Lightning Max Repair
- FAQ's

News & Media

- Press Releases
- MilwaukeeCain.com
- Product Reviews
- Media Center
- Media Inquiries

About Us

- Milwaukee Story
- Careers
- Locations
- Buy Now**
- Contact Us