



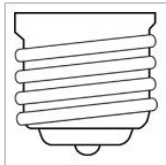

GE
Lighting

21025 - 300

GE Arcstream® PS35

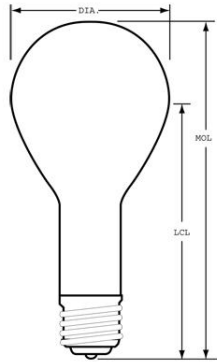

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	PS35
Base	Mogul Screw (E39)
Filament	C-9
Bulb Finish	Clear
Rated Life	1000.0 hrs
Bulb Material	Soft glass
Primary Application	Standard

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	5200.0
Nominal Initial Lumens per Watt	19

ELECTRICAL CHARACTERISTICS

Wattage	300.0
Voltage	130.0

DIMENSIONS

Maximum Overall Length (MOL)	9.3700 in(238.0 mm)
Bulb Diameter (DIA)	4.375 in(111.1 mm)
Light Center Length (LCL)	7.000 in(177.8 mm)

PRODUCT INFORMATION



Product Code	21025
Description	300
Standard Package	Case
Standard Package GTIN	10043168210253
Standard Package Quantity	24
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	24
UPC	043168210256



GE
Lighting

21025 - 300

GE Arcstream® PS35

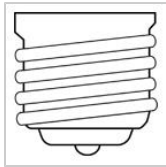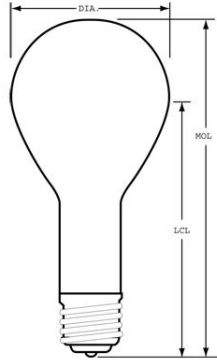

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	PS35
Base	Mogul Screw (E39)
Filament	C-9
Bulb Finish	Clear
Rated Life	1000.0 hrs
Bulb Material	Soft glass
Primary Application	Standard

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	5200.0
Nominal Initial Lumens per Watt	19

ELECTRICAL CHARACTERISTICS

Wattage	300.0
Voltage	130.0

DIMENSIONS

Maximum Overall Length (MOL)	9.3700 in(238.0 mm)
Bulb Diameter (DIA)	4.375 in(111.1 mm)
Light Center Length (LCL)	7.000 in(177.8 mm)

PRODUCT INFORMATION

Product Code	21025
Description	300
Standard Package	Case
Standard Package GTIN	10043168210253
Standard Package Quantity	24
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	24
UPC	043168210256