


## Zinc

### Images

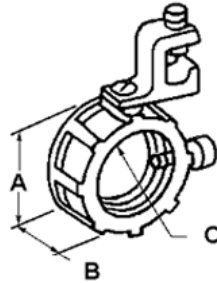

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 3-3/16

Dimension B in Inches: 13/16

Dimension C in Inches: 2-5/16

### Application

Used with locknut to terminate service conduit to cabinet. Lug provided for bonding jumper to neutral busbar. Grounding lug; aluminum alloy 6061-T6. Plastic metaliner prevents damage to wire insulation. Rated 150 degree C.

### Product Information

Material: Zinc Die Cast  
Finish: Ball burnished, mirror smooth,  
Grounding lug: Tin electro-plate

### Certifications & Codes:

Federal Specification Number: A-A-50553  
NEMA Standard: FB-1  
UL File Number: E20412  
UL Standard: UL-514B  
UNSPSC: 39121312

**Catalog ID:** 387-DC

**UPC Number:** 781747093875

**Description:** Bushing, Insulated, Grounding, Zinc Die Cast, Size 2-1/2 Inch, 14-1/0 Lug

**Application:** Used with locknut to terminate service conduit to cabinet. Lug provided for bonding jumper to neutral busbar. Grounding lug; aluminum alloy 6061-T6. Plastic metaliner prevents damage to wire insulation. Rated 150 degree C.

**Trade Size:** 2-1/2"

**Std Pkg Qty:** 25

**Unit Qty:** Bulk