


## Squeeze Type - Malleable Iron

### Images

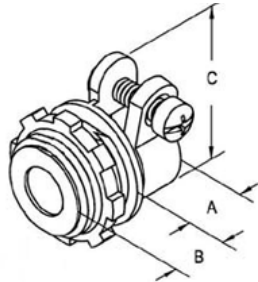

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1

Dimension B in Inches: 7/16

Dimension C in Inches: 1-1/2

Dimension D in Inches: .563

### Application

Used to connect flexible metal conduit to box or enclosure. Insulator rated 105 degree C.

### Product Information

Material: Malleable Iron

Finish: Zinc electro-plate

### Certifications & Codes:

UL File Number: E9391

UNSPSC: 39121419

**Catalog ID:** 407-I

**UPC Number:** 781747104076

**Description:** Connector, Squeeze, Malleable Iron, Insulated Throat, Trade Size 1/2 Inch

**Application:** Used to connect flexible metal conduit to box or enclosure. Insulator rated 105 degree C.

**Trade Size:** 1/2"

**Std Pkg Qty:** 200

**Unit Qty:** 50