






GE
Lighting

15206 - 40A15 CARD 12PK

GE appliance 40 watt A15 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's Appliance Lights can be used in many household appliances such as microwaves, refrigerators and ovens.
- 120 volts
- A15 shape with medium base for use in appliances
- Lasts 1500 hours
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens

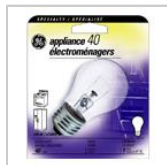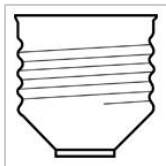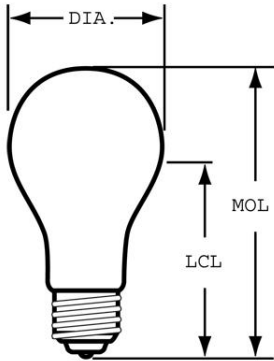

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	A15
Base	Medium Screw (E26)
Filament	C-9
Bulb Finish	Clear
Rated Life	1500.0 hrs
Bulb Material	Soft glass
Primary Application	Appliance;Standard;Ceiling Fan

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	415.0
Color Temperature	2600.0 K
Nominal Initial Lumens per Watt	10

ELECTRICAL CHARACTERISTICS

Wattage	40.0
Voltage	120.0

DIMENSIONS

Maximum Overall Length (MOL)	3.5000 in(88.9 mm)
Bulb Diameter (DIA)	1.875 in(47.6 mm)
Light Center Length (LCL)	2.370 in(60.2 mm)

PRODUCT INFORMATION

Product Code	15206
Description	40A15 CARD 12PK
Standard Package	BUNDLE
Standard Package GTIN	00043168152068
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	60
UPC	043168907071






GE
Lighting

15206 - 40A15 CARD 12PK

GE appliance 40 watt A15 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's Appliance Lights can be used in many household appliances such as microwaves, refrigerators and ovens.
- 120 volts
- A15 shape with medium base for use in appliances
- Lasts 1500 hours
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens

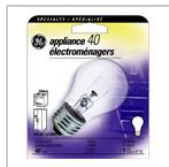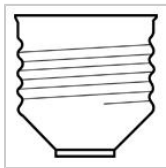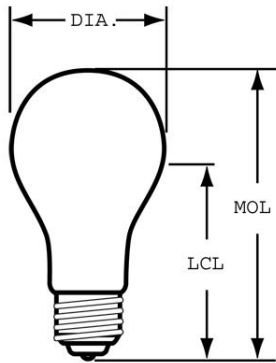

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	A15
Base	Medium Screw (E26)
Filament	C-9
Bulb Finish	Clear
Rated Life	1500.0 hrs
Bulb Material	Soft glass
Primary Application	Appliance;Standard;Ceiling Fan

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	415.0
Color Temperature	2600.0 K
Nominal Initial Lumens per Watt	10

ELECTRICAL CHARACTERISTICS

Wattage	40.0
Voltage	120.0

DIMENSIONS

Maximum Overall Length (MOL)	3.5000 in(88.9 mm)
Bulb Diameter (DIA)	1.875 in(47.6 mm)
Light Center Length (LCL)	2.370 in(60.2 mm)

PRODUCT INFORMATION

Product Code	15206
Description	40A15 CARD 12PK
Standard Package	BUNDLE
Standard Package GTIN	00043168152068
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	60
UPC	043168907071