


Squeeze Type - Zinc

Images

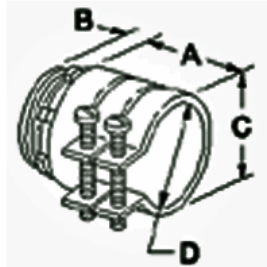

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-5/8
Dimension B in Inches: 13/16
Dimension C in Inches: 3-1/8
Dimension D in Inches: 1.896

Application

Used to connect flexible metal conduit or armored cable to box or enclosure. Insulator rated 105 degree C.

Product Information

Material: Zinc Die Cast
Finish: Ball burnished, mirror smooth

Certifications & Codes:

| | |
|-------------------------------|-----------|
| Federal Specification Number: | A-A-50552 |
| NEMA Standard: | FB-1 |
| UL File Number: | E9391 |
| UL Standard: | UL-514B |
| UNSPSC: | 39121419 |

Catalog ID: 416-DC12

UPC Number: 781747164162

Description: Connector, Squeeze, Zinc Die Cast, Insulated Throat, Trade Size 2 Inch

Application: Used to connect flexible metal conduit or armored cable to box or enclosure. Insulator rated 105 degree C.

Trade Size: 2"

Country of Manufacture: USA

Std Pkg Qty: 10

Unit Qty: Bulk