


Squeeze Type - Zinc

Images

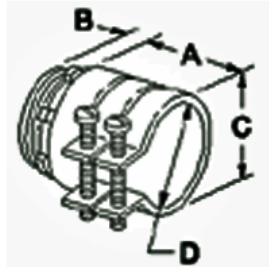

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 3-1/2
Dimension B in Inches: 1
Dimension C in Inches: 5-9/16
Dimension D in Inches: 4-1/2

Application

Used to connect flexible metal conduit or armored cable to box or enclosure.

Product Information

Material: Zinc Die Cast
Finish: Ball burnished, mirror smooth

Certifications & Codes:

Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121419

Catalog ID: 420-DC2

UPC Number: 781747154200

Description: Connector, Squeeze, Zinc Die Cast, Trade Size 4 Inch

Application: Used to connect flexible metal conduit or armored cable to box or enclosure.

Trade Size: 4"

Country of Manufacture: USA

Std Pkg Qty: 5

Unit Qty: Bulk