


Zinc

Images

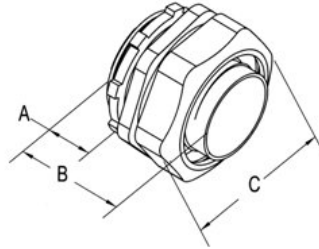

Application

Straight connector for use with metallic and non-metallic "Type B" liquid tight conduit. Insulator rated 105 degree C.

Product Information

Material: Zinc Die Cast
Finish: Ball burnished, mirror smooth

Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121420

[Download Photo Image](#) [Download Dimensional Image](#)

Dimension A in Inches: 15/16

Dimension B in Inches: 3/4

Dimension C in Inches: 1-7/16 Point to Point

Catalog ID: 430-LTI2

UPC Number: 781747164308

Description: Connector, Liquid Tight, Zinc Die Cast, Insulated Throat, Size 1/2 Inch

Application: Straight connector for use with metallic and non-metallic "Type B" liquid tight conduit. Insulator rated 105 degree C.

Trade Size: 1/2"

Std Pkg Qty: 100

Unit Qty: 25