


## Zinc

### Images

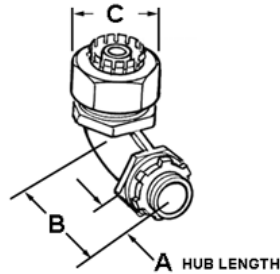

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 9/16

Dimension B in Inches: 2

Dimension C in Inches: 2-1/2

### Application

90 Degree connector for use with metallic and nonmetallic "Type B" liquid tight conduit. 1" and up cast zinc. Insulator rated 105 degree C.

### Product Information

Material: Zinc Cast

Finish: Zinc electro-plate

### Certifications & Codes:

CSA File Number: LR39354

Federal Specification Number: A-A-50552

NEMA Standard: FB-1

UL File Number: E9391

UL Standard: UL-514B

UNSPSC: 39121420

**Catalog ID:** 472-LTI2

**UPC Number:** 781747164728

**Description:** Connector, Liquid Tight, Die Cast Zinc, Insulated Throat, Size 1 Inch

**Application:** 90 Degree connector for use with metallic and nonmetallic "Type B" liquid tight conduit. 1" and up cast zinc. Insulator rated 105 degree C.

**Trade Size:** 1"

**Std Pkg Qty:** 25

**Unit Qty:** 5