


Home > ... > New Products > Shockwave Impact Duty™ Hex Drill Bits > 10PC SHOCKWAVE™ HEX DRILL BIT SET

10PC SHOCKWAVE™ HEX DRILL BIT SET 48-89-4445

PRINT

Tweet 813 Share 2643 ShareThis 6667

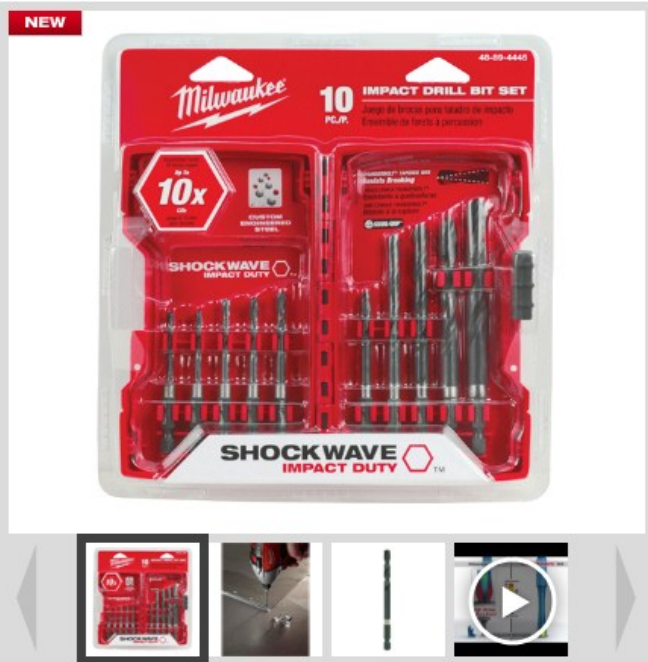

★★★★★ 0.0 Be the first to Write a Review

Milwaukee® Shockwave™ Impact Duty 1/4" Hex Drive Drill Bits are engineered for extreme durability and up to 10x life. Made from proprietary steel and heat treated to control hardness, the Shockwave™ Impact Duty Hex Drive Drill Bits feature the Milwaukee Thunderbolt® web for durability and chip removal. The bits include a 135° split point to allow the bit to start on contact and eliminates walking.

Includes

- Shockwave™ Impact Hex Drill Bits:
 - (2) 1/8"
 - (1) 9/64"
 - (1) 5/32"
 - (1) 11/64"
 - (1) 3/16"
 - (1) 7/32"
 - (1) 1/4"
 - (1) 5/16"
 - (1) 3/8"

FIND RE

FEATURES

- Proprietary steel and heat treat process for maximum strength and durability
- Thunderbolt® tapered web and parabolic flute for durability and chip removal
- 135° split point to start on contact and eliminates walking

SPECIFICATIONS

| | |
|------------------|---------|
| Diameter | Various |
| Package Quantity | 10 |

REVIEW SNAPSHOT® by PowerReviews

Not yet rated. Be the first to Write a Review

RELATED ITEMS



M12™ Cordless LITHIUM-ION 1/2" Hex Impact Driver



M18™ Cordless LITHIUM-ION 1/2" Hex Compact Impact Driver



M18™ Cordless LITHIUM-ION 1/2" Hex...



LITHIUM-ION 3/4" Hex
Compact Impact Driver

Sign Up for the
Heavy Duty Club



SUBMIT ▶

Products

- New Products & Offers
- Tools
- Accessories
- Test & Measurement
- Milwaukee Gear
- Print Current Catalog

Parts & Service

- e-SERVICE Tool Repair
- Test & Measure Service
- Find a Service Center
- Download Manuals
- Parts Pricing
- Milwaukee Warranty
- Lightning Max Repair
- FAQ's

News & Media

- Press Releases
- MilwaukeeCain.com
- Product Reviews
- Media Center
- Media Inquiries

About Us


- Milwaukee Story
- Careers
- Locations
- Buy Now**
- Contact Us

Home > ... > New Products > Shockwave Impact Duty™ Hex Drill Bits > 10PC SHOCKWAVE™ HEX DRILL BIT SET

10PC SHOCKWAVE™ HEX DRILL BIT SET 48-89-4445

PRINT

Tweet 813 Share 2643 ShareThis 6667

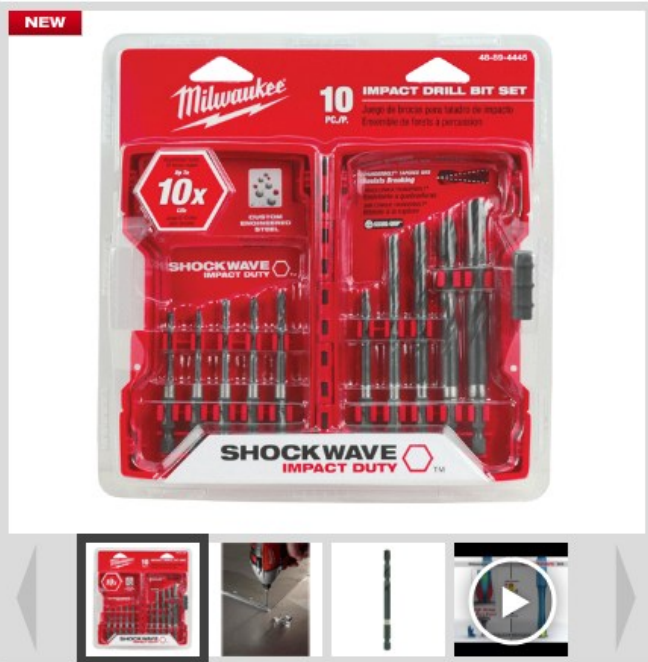

★★★★★ 0.0 Be the first to Write a Review

Milwaukee® Shockwave™ Impact Duty 1/4" Hex Drive Drill Bits are engineered for extreme durability and up to 10x life. Made from proprietary steel and heat treated to control hardness, the Shockwave™ Impact Duty Hex Drive Drill Bits feature the Milwaukee Thunderbolt® web for durability and chip removal. The bits include a 135° split point to allow the bit to start on contact and eliminates walking.

Includes

- Shockwave™ Impact Hex Drill Bits:
 - (2) 1/8"
 - (1) 9/64"
 - (1) 5/32"
 - (1) 11/64"
 - (1) 3/16"
 - (1) 7/32"
 - (1) 1/4"
 - (1) 5/16"
 - (1) 3/8"

FIND RE

FEATURES

- Proprietary steel and heat treat process for maximum strength and durability
- Thunderbolt® tapered web and parabolic flute for durability and chip removal
- 135° split point to start on contact and eliminates walking

SPECIFICATIONS

| | |
|------------------|---------|
| Diameter | Various |
| Package Quantity | 10 |

REVIEW SNAPSHOT® by PowerReviews

Not yet rated. Be the first to Write a Review

RELATED ITEMS



M12™ Cordless LITHIUM-ION 1/2" Hex Impact Driver



M18™ Cordless LITHIUM-ION 1/4" Hex Compact Impact Driver



M18™ Cordless LITHIUM-ION 1/2" Hex Impact Driver



LITHIUM-ION 3/4" Hex
Compact Impact Driver

Sign Up for the
Heavy Duty Club



SUBMIT ▶

Products

- New Products & Offers
- Tools
- Accessories
- Test & Measurement
- Milwaukee Gear
- Print Current Catalog

Parts & Service

- e-SERVICE Tool Repair
- Test & Measure Service
- Find a Service Center
- Download Manuals
- Parts Pricing
- Milwaukee Warranty
- Lightning Max Repair
- FAQ's

News & Media

- Press Releases
- MilwaukeeCain.com
- Product Reviews
- Media Center
- Media Inquiries

About Us

- Milwaukee Story
- Careers
- Locations
- Buy Now**
- Contact Us