

SNAP²IT[®] MC Cable Connectors

with Locknut • Easy Snap-in Cable Insertion • NO TOOLS!



1/2" KO
3838A
installed in
light fixture
with locknut


Easy, snap
onto cable
installation

Snap on
side

Threaded
side

4040A
1/2" KO

Snaps
onto cable
**SAVES 12
SECONDS
per connector**

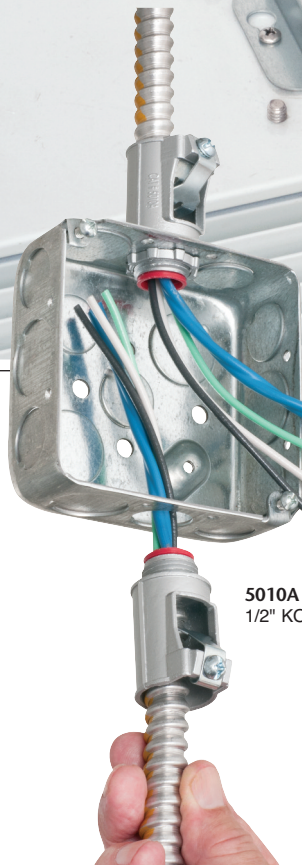

Ideal
for MC-PCS
conduit

5010A
1/2" KO

38A

40A

3838A

4040A

505010A

Locknut
attachment
in box

Arlington's SNAP²IT[®] fittings with locknuts deliver a fast, safe installation.

Fitting-on-cable installation is easy, and requires NO TOOLS! Just snap the fitting onto cable and twist clockwise. Tangs inside the fitting hold the cable secure.




With this series the assembly installs into the knockout with a LOCKNUT.

The red tinting in the 40A, 4010A and 4040A indicates our 'OPEN TANG' design, meaning more room inside the fitting for easy insertion of wires.

- **Widest total cable ranges**
14/2 to 6/3
- **Widest variety of cables**
For AC, MCI-A, HCF steel and aluminum, steel and aluminum flexible metal conduit, MCI cable, continuous corrugated aluminum, AC90 and ACG90
- **Secure installation** No pullout
- Meets UL ground fault requirements
- **Fully assembled – Ready to use – Reusable connector**
For 1/2" KO, in single and duplex styles, all with insulated throat

Patented

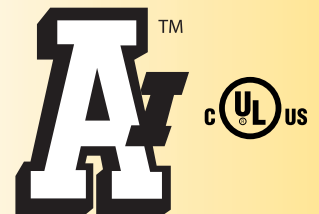

Arlington[®]

1 Stauffer Industrial Park
Scranton, PA 18517
800/233.4717 • Fax 570/562.0646
www.aifittings.com

CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION SNAP ON FITTINGS	CABLE TRADE SIZE	KO SIZE	CABLE (OD) OUTSIDE DIA.	CABLE SIZE	UNIT PKG	STD PKG
38A	00038	Single gang, SILVER inside	3/8"	1/2"	.405 to .610	14/2 & 12/2 w and w/o ground, 14/3, 14/4,	50	500
3838A	36200	Duplex, SILVER inside	3/8"	1/2"	(2) .405 to .610	12/3, 12/4, 10/2, 10/3	25	100
40A	48015	Single gang, RED TINT Open Tang	3/8"	1/2"	.485 to .610	14/3, 12/2 & 12/3 w and w/o ground, 14/4,	50	500
4010A	11420	Single gang, RED TINT Open Tang	3/8"	1/2"	.405 to .610	12/4, 10/2, 10/3	50	500
4040A	40350	Duplex, RED TINT Open Tang	3/8"	1/2"	(2) .485 to .610		25	100
5010A	01299	Single gang, SILVER inside	1/2"	1/2"	.580 to .780	10/3 to 6/3	25	250
505010A	76214	Duplex, SILVER inside	1/2"	3/4"	(2) .590 to .820		25	25

SNAP²IT[®] MC Cable Connectors

with Locknut • Easy Snap-in Cable Insertion • NO TOOLS!



1/2" KO
3838A
installed in
light fixture
with locknut


Easy, snap
onto cable
installation

Snap on
side

Threaded
side

4040A
1/2" KO

Snap
onto cable
**SAVES 12
SECONDS
per connector**

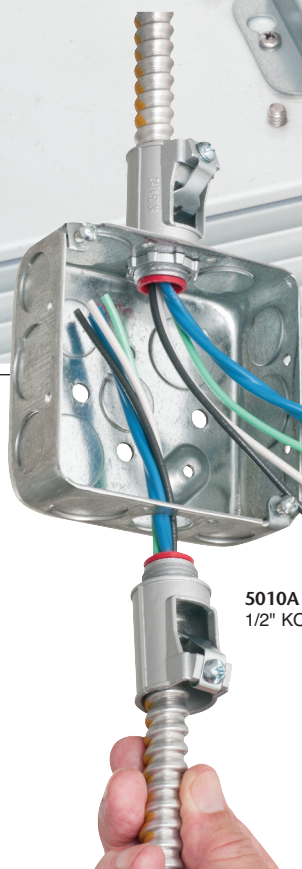

Ideal
for MC-PCS
conduit

5010A
1/2" KO



38A



40A



3838A



4040A



505010A

Locknut
attachment
in box

Arlington's SNAP²IT[®] fittings with locknuts deliver a fast, safe installation.

Fitting-on-cable installation is easy, and requires NO TOOLS! Just snap the fitting onto cable and twist clockwise. Tangs inside the fitting hold the cable secure.



3838A
1/2" KO

With this series the assembly installs into the knockout with a LOCKNUT.



The red tinting in the 40A, 4010A and 4040A indicates our 'OPEN TANG' design, meaning more room inside the fitting for easy insertion of wires.

- **Widest total cable ranges**
14/2 to 6/3
- **Widest variety of cables**
For AC, MCI-A, HCF steel and aluminum, steel and aluminum flexible metal conduit, MCI cable, continuous corrugated aluminum, AC90 and ACG90
- **Secure installation** No pullout
- Meets UL ground fault requirements
- **Fully assembled – Ready to use – Reusable connector**
For 1/2" KO, in single and duplex styles, all with insulated throat

Patented



Arlington[®]

1 Stauffer Industrial Park
Scranton, PA 18517
800/233.4717 • Fax 570/562.0646
www.aifittings.com

CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION SNAP ON FITTINGS	CABLE TRADE SIZE	KO SIZE	CABLE (OD) OUTSIDE DIA.	CABLE SIZE	UNIT PKG	STD PKG
38A	00038	Single gang, SILVER inside	3/8"	1/2"	.405 to .610	14/2 & 12/2 w and w/o ground, 14/3, 14/4,	50	500
3838A	36200	Duplex, SILVER inside	3/8"	1/2"	(2) .405 to .610	12/3, 12/4, 10/2, 10/3	25	100
40A	48015	Single gang, RED TINT Open Tang	3/8"	1/2"	.485 to .610	14/3, 12/2 & 12/3 w and w/o ground, 14/4, 12/4, 10/2, 10/3	50	500
4010A	11420	Single gang, RED TINT Open Tang	3/8"	1/2"	.405 to .610		50	500
4040A	40350	Duplex, RED TINT Open Tang	3/8"	1/2"	(2) .485 to .610		25	100
5010A	01299	Single gang, SILVER inside	1/2"	1/2"	.580 to .780		25	250
505010A	76214	Duplex, SILVER inside	1/2"	3/4"	(2) .590 to .820		25	25