




GE  
Lighting

## 17874 - 50PAR30/H/FL35

### GE energy-efficient halogen 46/50 watt PAR30 floodlight 1-pack

• GE energy-efficient halogen bulbs deliver crisp, white light. This unsurpassed light quality is ideal for adding depth, drama and interest to any room. These GE energy-efficient halogen floodlights use less energy than standard halogen bulbs, saving money on energy. GE energy-efficient halogen floodlights feature lenses designed to provide a precise beam pattern, dispensing broad beams of crisp, white light throughout your home's interior. Use these bulbs in indoor track and recessed fixtures instead of regular incandescent and create a dramatic effect

- Estimated yearly energy costs \$6.02 based on 3 hours per day \$0.11 per kWh
- Lasts 2.7 years based on 3 hours per day usage
- PAR30 indoor floodlight with medium base for use in directional fixtures such as recessed can lighting

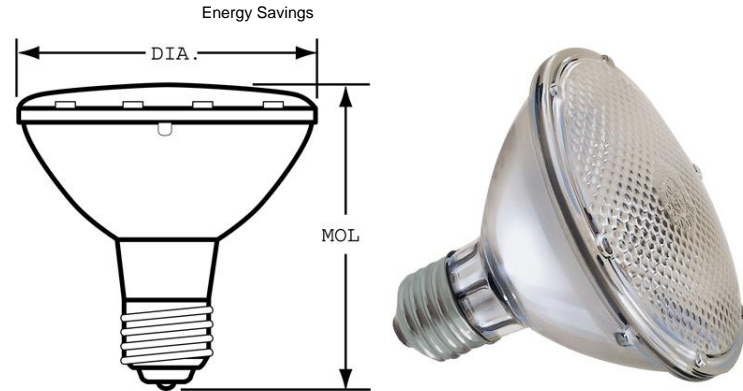

### CAUTIONS & WARNINGS

#### Caution

- Lamp may shatter and cause injury if broken
  - Do not use lamp if outer glass is scratched or broken.

#### Warning

- Risk of Burn
  - Allow lamp to cool before handling.
- Risk of Fire
  - Keep combustible materials away from lamp.
- Risk of Electric Shock
  - Turn power off before inspection, installation or removal.
- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
  - Do not use lamp if outer glass is scratched or broken.
  - Do not use where directly exposed to water or outdoors without an enclosed fixture.

### GENERAL CHARACTERISTICS

Lamp Type	Halogen - PAR
Bulb	PAR30
Base	Medium NP
Filament	CC-8
Rated Life	3000.0 hrs

### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	630.0 /500.0
Center Beam Candlepower (CBCP)	1400.0
Color Temperature	2800.0 K
Beam Spread	35.0 °
Nominal Initial Lumens per Watt	12 /10

### ELECTRICAL CHARACTERISTICS

Wattage	50.0
Voltage	130.0

### DIMENSIONS

Maximum Overall Length (MOL)	3.6200 in(91.9 mm)
Bulb Diameter (DIA)	3.750 in(95.2 mm)

### PRODUCT INFORMATION

Product Code	17874
Description	50PAR30/H/FL35
Standard Package	Case
Standard Package GTIN	00043168178747
Standard Package Quantity	15
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	15
UPC	043168970174




GE  
Lighting

## 17874 - 50PAR30/H/FL35

### GE energy-efficient halogen 46/50 watt PAR30 floodlight 1-pack

• GE energy-efficient halogen bulbs deliver crisp, white light. This unsurpassed light quality is ideal for adding depth, drama and interest to any room. These GE energy-efficient halogen floodlights use less energy than standard halogen bulbs, saving money on energy. GE energy-efficient halogen floodlights feature lenses designed to provide a precise beam pattern, dispensing broad beams of crisp, white light throughout your home's interior. Use these bulbs in indoor track and recessed fixtures instead of regular incandescent and create a dramatic effect

- Estimated yearly energy costs \$6.02 based on 3 hours per day \$0.11 per kWh
- Lasts 2.7 years based on 3 hours per day usage
- PAR30 indoor floodlight with medium base for use in directional fixtures such as recessed can lighting

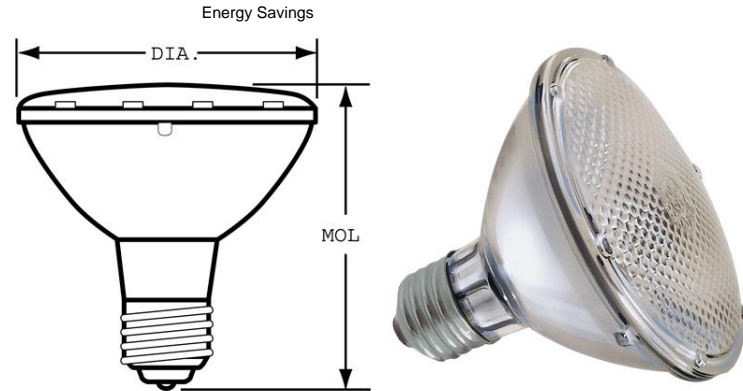

### CAUTIONS & WARNINGS

#### Caution

- Lamp may shatter and cause injury if broken
  - Do not use lamp if outer glass is scratched or broken.

#### Warning

- Risk of Burn
  - Allow lamp to cool before handling.
- Risk of Fire
  - Keep combustible materials away from lamp.
- Risk of Electric Shock
  - Turn power off before inspection, installation or removal.
- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
  - Do not use lamp if outer glass is scratched or broken.
  - Do not use where directly exposed to water or outdoors without an enclosed fixture.

### GENERAL CHARACTERISTICS

Lamp Type	Halogen - PAR
Bulb	PAR30
Base	Medium NP
Filament	CC-8
Rated Life	3000.0 hrs

### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	630.0 /500.0
Center Beam Candlepower (CBCP)	1400.0
Color Temperature	2800.0 K
Beam Spread	35.0 °
Nominal Initial Lumens per Watt	12 /10

### ELECTRICAL CHARACTERISTICS

Wattage	50.0
Voltage	130.0

### DIMENSIONS

Maximum Overall Length (MOL)	3.6200 in(91.9 mm)
Bulb Diameter (DIA)	3.750 in(95.2 mm)

### PRODUCT INFORMATION

Product Code	17874
Description	50PAR30/H/FL35
Standard Package	Case
Standard Package GTIN	00043168178747
Standard Package Quantity	15
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	15
UPC	043168970174