
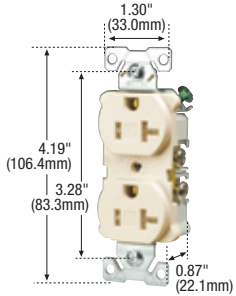



Construction grade straight blade receptacles

Product description


2-pole, 3-wire grounding
 15A, 125V/AC
 20A, 125V/AC
 NEMA 5-15R, 5-20R

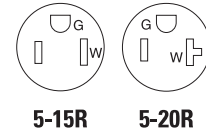

TR5362

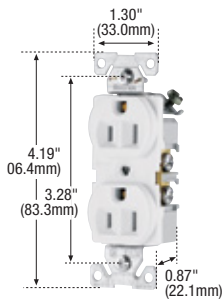

5262

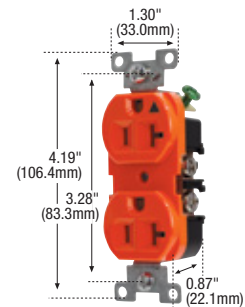

IG5362

Tamper resistant construction grade receptacles



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.	▶	🇺🇸	✓
15	125	5-15R	Duplex receptacle, back & side wire	A, B, BK, GY, LA, V, W	□ TR5262__	•	•	•	
20	125	5-20R	Duplex receptacle, back & side wire	A, B, BK, GY, LA, RD, V, W	□ TR5362__	•	•	•	

Construction grade receptacles




Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.	▶	🇺🇸	✓
15	125	5-15R	Duplex receptacle, back & side wire	B, GY, LA, V, W	□ 5262__	•	•	•	•
20	125	5-20R	Duplex receptacle, back & side wire	B, BK, BL, GY, LA, RD, V, W	□ 5362__	•	•	•	•

Construction grade straight blade receptacles

Product description

2-pole, 3-wire grounding
 15A, 250V/AC
 20A, 250V/AC
 NEMA 5-15R, 5-20R, 6-15R, 6-20R

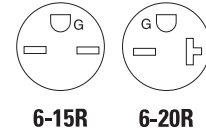

Construction grade receptacles



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.	▶	🇺🇸	✓
15	250	6-15R	Duplex receptacle, back & side wire	B, V, W	□ 5662C__ [†]	•	•	•	
20	250	6-20R	Duplex receptacle, back & side wire	B, V, W	□ 5462C__	•	•	•	

[†] Not NOM cert

Isolated ground, back wire & side wire



Rating	A	V/AC	NEMA	Description	Color suffix	Catalog no.	✓
15	125	5-15R	IG duplex receptacle	GY, RD, RN, V, W	□ IG5262__	•	
20	125	5-20R	IG duplex receptacle	BK, GY, RD, RN, V, W	□ IG5362__	•	

Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: A (Almond), B (Brown), BK (Black), BL (Blue), GY (Gray), LA (Light Almond), RD (Red), RN (Orange), V (Ivory), W (White)

A	B	BK	BL	GY	LA	RD	RN	V	W
(Almond)	(Brown)	(Black)	(Blue)	(Gray)	(Lt. Almond)	(Red)	(Orange)	(Ivory)	(White)

Specification information: Construction grade receptacles: A-31, ArrowLink construction grade receptacles: A-36, Tamper resistant construction grade receptacles: A-32

Compliances, specifications and availability are subject to change without notice.

▶ ArrowLink option available. Add "M" suffix to standard catalog number (example AH8300W, AH8300WM). For ordering information on ArrowLink & ArrowLink SPD connectors, see Page A-5

🇺🇸 Build-to-spec customizable devices - Page A-6

🇺🇸 Indicates NAFTA compliant - Page Q-32

TR Tamper resistant



✓ RoHS compliant - Page Q-32

Construction grade receptacles

Construction grade straight blade receptacles

Product description

2-pole, 3-wire grounding
 15A, 125V/AC
 20A, 125V/AC
 NEMA 5-15R, 5-20R

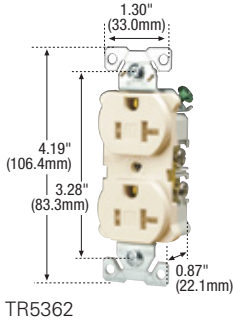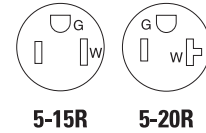

Tamper resistant construction grade receptacles



Rating									
A	V/AC	NEMA	Description	Color suffix	Catalog no.				
15	125	5-15R	Duplex receptacle, back & side wire	A, B, BK, GY, LA, V, W	□ TR5262__	•	•	•	•
20	125	5-20R	Duplex receptacle, back & side wire	A, B, BK, GY, LA, RD, V, W	□ TR5362__	•	•	•	•

Construction grade receptacles





Rating									
A	V/AC	NEMA	Description	Color suffix	Catalog no.				
15	125	5-15R	Duplex receptacle, back & side wire	B, GY, LA, V, W	□ 5262__	•	•	•	•
20	125	5-20R	Duplex receptacle, back & side wire	B, BK, BL, GY, LA, RD, V, W	□ 5362__	•	•	•	•

Construction grade straight blade receptacles

Product description

2-pole, 3-wire grounding
 15A, 250V/AC
 20A, 250V/AC
 NEMA 5-15R, 5-20R, 6-15R, 6-20R

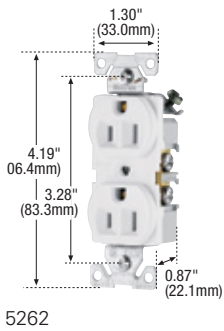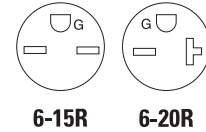

Construction grade receptacles




Rating									
A	V/AC	NEMA	Description	Color suffix	Catalog no.				
15	250	6-15R	Duplex receptacle, back & side wire	B, V, W	□ 5662C__ [†]	•	•	•	•
20	250	6-20R	Duplex receptacle, back & side wire	B, V, W	□ 5462C__	•	•	•	•

[†] Not NOM cert

Isolated ground, back wire & side wire



Rating									
A	V/AC	NEMA	Description	Color suffix	Catalog no.				
15	125	5-15R	IG duplex receptacle	GY, RD, RN, V, W	□ IG5262__				•
20	125	5-20R	IG duplex receptacle	BK, GY, RD, RN, V, W	□ IG5362__				•

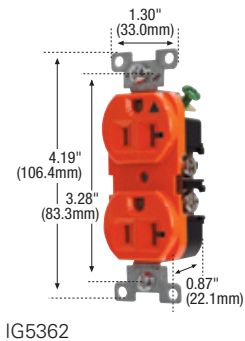

Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: A (Almond), B (Brown), BK (Black), BL (Blue), GY (Gray), LA (Light Almond), RD (Red), RN (Orange), V (Ivory), W (White)

A	B	BK	BL	GY	LA	RD	RN	V	W
(Almond)	(Brown)	(Black)	(Blue)	(Gray)	(Lt. Almond)	(Red)	(Orange)	(Ivory)	(White)

Specification information: Construction grade receptacles: A-31, ArrowLink construction grade receptacles: A-36, Tamper resistant construction grade receptacles: A-32

Compliances, specifications and availability are subject to change without notice.

➡ ArrowLink option available. Add "M" suffix to standard catalog number (example AH8300W, AH8300WM). For ordering information on ArrowLink & ArrowLink SPD connectors, see Page A-5

🏠 Build-to-spec customizable devices - Page A-6

🇺🇸 Indicates NAFTA compliant - Page Q-32

🔒 Tamper resistant

♻️ RoHS compliant - Page Q-32