




4 IN. ROUND BOX & EXTENSION

**1-1/2 in. Deep - Five Threaded Outlets - 4 in. Round Splice Box
N/A**

D08

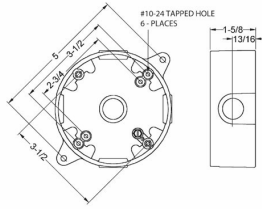

Catalog #: 5372-0

APPLICATIONS

For use in branch circuit wiring in wet, damp, or dry locations
May be used as a weatherproof junction box, and may be used with BELL® round cluster covers and round lampholder combinations

PRODUCT FEATURES

- Reinforced connector outlets
- State-of-the-art powder coat finish provides maximum weatherability and scratch resistance
- Cast-in mounting lugs provide fast, secure installation
- Four closure plugs included
- Hubs accept all threaded fittings and threaded conduit
- Ground screw installed
- Multi-lingual instructions in each package
- Includes gasket and mounting hardware
- N/A

UL LISTED

File E195978

CSA

C22.2 No. 18

NEMA

3R Rated

GENERAL PRODUCT INFORMATION

Color: Gray

CONFIGURATION

Number Of Outlets: 5

PRODUCT MEASUREMENTS

Depth: 1-1/2 in.
 Outlet Size: 3/4 in.
 Cubic Inches (cm3): 16.0 (262.2)
 Wt. Ea. (Lbs.): 0.580

PACKAGING


Package Type: Shrink
 Std. Pkg.: 16
 Product UPC-A Labeled: Yes
 Weight (Lbs. Per/C): 58.00
 Ship Carton Length (in.): 16.19
 Ship Carton Width (in.): 6.50
 Ship Carton Height (in.): 8.50
 Ctn Weight (Lbs.): 10.15
 Pallet Qty: 1440.00
 UPC Number: 050169537206
 I2of5: 50050169537201



4 IN. ROUND BOX & EXTENSION

**1-1/2 in. Deep - Five Threaded Outlets - 4 in. Round Splice Box
N/A**

D08

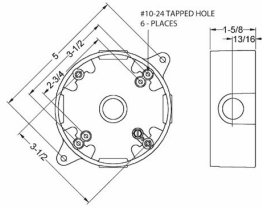

Catalog #: 5372-0

APPLICATIONS

For use in branch circuit wiring in wet, damp, or dry locations
May be used as a weatherproof junction box, and may be used with BELL® round cluster covers and round lampholder combinations

PRODUCT FEATURES

- Reinforced connector outlets
- State-of-the-art powder coat finish provides maximum weatherability and scratch resistance
- Cast-in mounting lugs provide fast, secure installation
- Four closure plugs included
- Hubs accept all threaded fittings and threaded conduit
- Ground screw installed
- Multi-lingual instructions in each package
- Includes gasket and mounting hardware
- N/A

UL LISTED

File E195978

CSA

C22.2 No. 18

NEMA

3R Rated

GENERAL PRODUCT INFORMATION

Color: Gray

CONFIGURATION

Number Of Outlets: 5

PRODUCT MEASUREMENTS

Depth: 1-1/2 in.
 Outlet Size: 3/4 in.
 Cubic Inches (cm3): 16.0 (262.2)
 Wt. Ea. (Lbs.): 0.580

PACKAGING

Package Type: Shrink
 Std. Pkg.: 16
 Product UPC-A Labeled: Yes
 Weight (Lbs. Per/C): 58.00
 Ship Carton Length (in.): 16.19
 Ship Carton Width (in.): 6.50
 Ship Carton Height (in.): 8.50
 Ctn Weight (Lbs.): 10.15
 Pallet Qty: 1440.00
 UPC Number: 050169537206
 I2of5: 50050169537201