



GE
Lighting

78797 - 53A/CL/H-2PK



GE energy-efficient crystal clear 43 watt A19 2-pack

• GE energy-efficient crystal clear bulbs have the same look, feel and nearly the same brightness as traditional incandescents, but with one big change: it now pays you back! These bulbs use 28% less energy than regular incandescents, helping you save money on energy costs. Add sparkle and a decorative touch to fixtures where the bulb is visible with GE energy-efficient crystal clear bulbs

- 60 watt replacement uses only 43 watts
- A19 shape with medium base for use in table lamps and enclosed fixtures
- Estimated yearly energy costs \$5.18 based on 3 hours per day \$0.11 per kWh
- Lasts 0.9 years based on 3 hours per day usage

Energy Savings

Reduced Wattage
Meets Federal Minimum Efficiency Standards

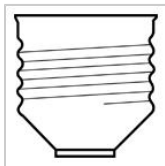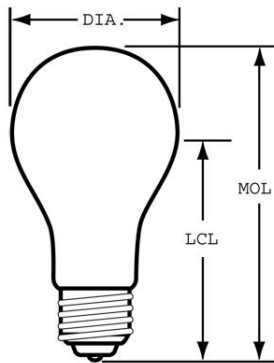

GENERAL CHARACTERISTICS

Lamp Type	Halogen - A-line
Bulb	A19
Base	Medium Screw (E26)
Filament	CC-8
Bulb Finish	Clear reveal®
Rated Life (NOM)	1000.0 h
Bulb Material	Sodalime glass
Life in Years (NOM)	0.9
Additional Info	Dimmable on standard incandescent dimmer.
Primary Application	Standard

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	1050.0
Color Temperature (NOM)	2950.0 K
Color Rendering Index (CRI) (NOM)	100.0
Nominal Initial Lumens per Watt (NOM)	19.81

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	53.0
Voltage (NOM)	120.0
Burn Position	Universal
Estimated Energy Cost per Year (NOM)	6.38

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	4.430 in(112.5 mm)
Bulb Diameter (DIA) (NOM)	2.375 in(60.3 mm)

PRODUCT INFORMATION

Product Code	78797
Description	53A/CL/H-2PK
Standard Package	00-Case
Standard Package GTIN	10043168787977
Standard Package Quantity	6
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	043168787970



GE
Lighting

78797 - 53A/CL/H-2PK



GE energy-efficient crystal clear 43 watt A19 2-pack

• GE energy-efficient crystal clear bulbs have the same look, feel and nearly the same brightness as traditional incandescents, but with one big change: it now pays you back! These bulbs use 28% less energy than regular incandescents, helping you save money on energy costs. Add sparkle and a decorative touch to fixtures where the bulb is visible with GE energy-efficient crystal clear bulbs

- 60 watt replacement uses only 43 watts
- A19 shape with medium base for use in table lamps and enclosed fixtures
- Estimated yearly energy costs \$5.18 based on 3 hours per day \$0.11 per kWh
- Lasts 0.9 years based on 3 hours per day usage

Energy Savings

Reduced Wattage
Meets Federal Minimum Efficiency Standards

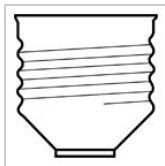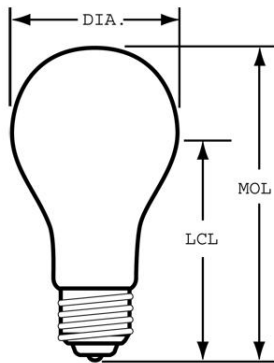

GENERAL CHARACTERISTICS

Lamp Type	Halogen - A-line
Bulb	A19
Base	Medium Screw (E26)
Filament	CC-8
Bulb Finish	Clear reveal®
Rated Life (NOM)	1000.0 h
Bulb Material	Sodalime glass
Life in Years (NOM)	0.9
Additional Info	Dimmable on standard incandescent dimmer.
Primary Application	Standard

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	1050.0
Color Temperature (NOM)	2950.0 K
Color Rendering Index (CRI) (NOM)	100.0
Nominal Initial Lumens per Watt (NOM)	19.81

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	53.0
Voltage (NOM)	120.0
Burn Position	Universal
Estimated Energy Cost per Year (NOM)	6.38

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	4.430 in(112.5 mm)
Bulb Diameter (DIA) (NOM)	2.375 in(60.3 mm)

PRODUCT INFORMATION

Product Code	78797
Description	53A/CL/H-2PK
Standard Package	00-Case
Standard Package GTIN	10043168787977
Standard Package Quantity	6
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	043168787970