


## Cable Snap-in - Zinc

### Images

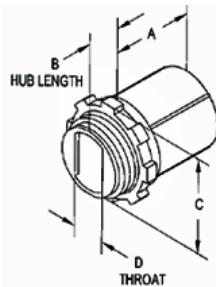

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 15/16

Dimension B in Inches: 3/8

Dimension C in Inches: 1-1/16

Dimension D in Inches: 3/8

### Application

Recommended cable types with Steel or Aluminum 14/2 to 10/3 AC or MC Cable, or 3/8" Flexible Metal Conduit to box or enclosure. Diameter for 14/2 (.43" 0 min) to 10/3 (.61" 0 max)

### Product Information

Material: Zinc Die Cast with Spring Steel Inner  
Locking Ring  
Finish: Ball Burnished, Mirror Smooth

### Certifications & Codes:

Federal Specification Number: A-A-50552  
NEMA Standard: FB-1  
UL File Number: E20534  
UL Standard: UL514B  
UNSPSC: 39121419

**Catalog ID:** 590-DC2

**UPC Number:** 781747155900

**Description:** AC/MC Snap Type Connector

**Application:** Recommended cable types with Steel or Aluminum 14/2 to 10/3 AC or MC Cable, or 3/8" Flexible Metal Conduit to box or enclosure. Diameter for 14/2 (.43" 0 min) to 10/3 (.61" 0 max)

**Trade Size:** 3/8"

**Country of Manufacture:** USA

**Std Pkg Qty:** 500

**Unit Qty:** 50