


SJO (Oval) Cable - Two Screw - Strap Type

Images

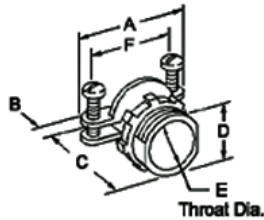

Application

For connecting nonmetallic cable to box or enclosure.
It can be used for one or two cables.

Product Information

Material: Zinc Die Cast
Finish: Ball burnished, mirror smooth

Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E11698
UL Standard:	UL-514B
UNSPSC:	39121419

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-5/16
Dimension B in Inches: 3/8
Dimension C in Inches: 3/8
Dimension D in Inches: 13/16
Dimension E in Inches: .625
Dimension F in Inches: 15/16

Catalog ID: 650-DC2

UPC Number: 781747156501

Description: Connector, Strap, Two Screw, Zinc Die Cast, Oval Cable, Size K.O. 1/2 Inch

Application: For connecting nonmetallic cable to box or enclosure. It can be used for one or two cables.

Trade Size: 1/2"

Country of Manufacture: USA

Std Pkg Qty: 1000

Unit Qty: 100