


SJO (Oval) Cable - Two Screw - Strap Type

Images

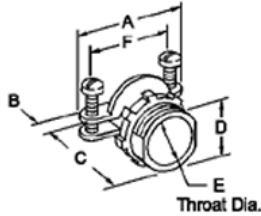

Application

For connecting nonmetallic cable to box or enclosure.

Product Information

Material: Zinc Die Cast
Finish: Ball burnished, mirror smooth

Certifications & Codes:

| | |
|-------------------------------|-----------|
| CSA File Number: | LR39354 |
| Federal Specification Number: | A-A-50552 |
| NEMA Standard: | FB-1 |
| UL File Number: | E15123 |
| UL Standard: | UL-514B |
| UNSPSC: | 39121419 |

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 2-7/8
Dimension B in Inches: 5/8
Dimension C in Inches: 3/4
Dimension D in Inches: 2-3/8
Dimension E in Inches: 1.500
Dimension F in Inches: 2-1/4

Catalog ID: 675-DC2

UPC Number: 781747156754

Description: Connector, Strap, Two Screw, Zinc Die Cast, Oval Cable, Size K.O. 1 1/2 Inch

Application: For connecting nonmetallic cable to box or enclosure.

Trade Size: 1-1/2"

Std Pkg Qty: 25

Unit Qty: Bulk