


## SJO (Oval) Cable - Two Screw - Strap Type

### Images

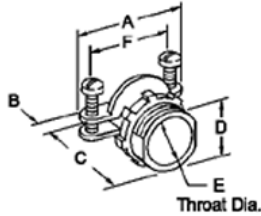

### Application

For connecting nonmetallic cable to box or enclosure.

### Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth

### Certifications & Codes:

CSA File Number: LR39354

Federal Specification Number: A-A-50552

NEMA Standard: FB-1

UL File Number: E15123

UL Standard: UL-514B

UNSPSC: 39121419

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 3-1/2

Dimension B in Inches: 3/4

Dimension C in Inches: 13/16

Dimension D in Inches: 2-5/8

Dimension E in Inches: 1.968

Dimension F in Inches: 2-3/4

**Catalog ID:** 676-DC2

**UPC Number:** 781747156761

**Description:** Connector, Strap, Two Screw, Zinc Die Cast, Oval Cable, Size K.O. 2 Inch

**Application:** For connecting nonmetallic cable to box or enclosure.

**Trade Size:** 2"

**Std Pkg Qty:** 25

**Unit Qty:** Bulk