


## Duplex - "U" Strap Type - Zinc

### Images

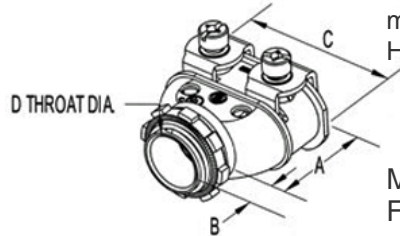

### Application

Recommended cable types for connecting 14/2 (.42" min) to 10/3 (.61" max) armored or metal clad cable or HCF to box or enclosure. AC/MC/MCI-A

### Product Information

Material: Zinc Die Cast  
Finish: Ball Burnished, Mirror Smooth

### Certifications & Codes:

NEMA Standard: FB-1  
UL Standard: UL-514B  
UNSPSC: 39121419

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1.18  
Dimension B in Inches: .38  
Dimension C in Inches: 1.74  
Dimension D in Inches: .63

**Catalog ID:** 691-DC2

**UPC Number:** 78174715691

**Description:** Connector, Strap Type, Duplex, Zinc Die Cast, Size K.O. 1/2 inch.

**Application:** Recommended cable types for connecting 14/2 (.42" min) to 10/3 (.61" max) armored or metal clad cable or HCF to box or enclosure. AC/MC/MCI-A

**Trade Size:** 3/8"

**Std Pkg Qty:** 200

**Unit Qty:** 20