

## Sign and Scoreboard Lighting

Attachon Lampholders,  
660W, 250V/AC  
200W, 250V/AC  
75W, 125V/AC  
75W, 250V/AC

### Medium Base Attachon

#### FEATURES

- Insulation displacement terminals for stranded wire.
- Lay in wire channels, 1/4 turn twist top speeds installation.
- One piece terminals and contacts, no rivets or eyelets to loosen due to heat.
- Sockets are molded of heat-resistant phenolic.
- #732 is weatherproof, suitable for outdoor use.
- Intermediate and candelabra bases offer snap-in or screw-in panel mounting options.
- Keyed spring washer prevents rotation of socket after installation.




732




732-3



4734-2

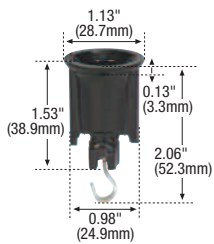

731

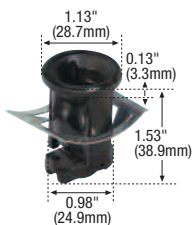

731-2



731-3

### Sign and Scoreboard Lampholders

Rating W V/AC	Product Type	Catalog No.			
660 250	Weatherproof Phenolic, Wire Range #14 to #12 AWG, Hook Mounting	<input type="checkbox"/> 732			
	Weatherproof Phenolic, Wire Range #14 to #12 AWG, No Hook Mounting	<input type="checkbox"/> 732-1			
	Weatherproof Phenolic, Wire Range #14 to #12 AWG, Snap-in Mounting	<input type="checkbox"/> 732-3			
	Phenolic, Wire Range #18 to #12 AWG, Snap-in Mounting	<input type="checkbox"/> 4734-2			
	Phenolic, Wire Range #14 to #12 AWG, Screws Mounting	<input type="checkbox"/> 734			

For panel cutout dimensional data, see section O-Technical Reference

### Medium Base Attachon with Guard

#### Sign and Scoreboard Lampholder

Rating W V/AC	Product Type	Catalog No.		
200 250	Phenolic Socket (732), Yellow Guard, Wire Range #18 to #12 AWG, Hook Mounting	<input type="checkbox"/> 1466Y		

### Intermediate Base Attachon

#### Sign and Scoreboard Lampholders

Rating W V/AC	Product Type	Catalog No.			
75 250	Phenolic, Wire Range #18 to #16 AWG, Hook Mounting	<input type="checkbox"/> 731			
	Phenolic, Wire Range #18 to #16 AWG, No Hook Mounting	<input type="checkbox"/> 731-1*			
	Phenolic, Wire Range #18 to #16 AWG, Spring Washer Mounting	<input type="checkbox"/> 731-2*			
	Phenolic, Wire Range #18 to #16 AWG, Snap-in Mounting	<input type="checkbox"/> 731-3			

For panel cutout dimensional data, see O-Technical Reference

\* Not CSA certified

### Candelabra Base Attachon

#### Sign and Scoreboard Lampholders

Rating W V/AC	Product Type	Catalog No.			
75 125	Phenolic, Wire Range #20 to #18 AWG, No Hook Mounting	<input type="checkbox"/> 974			
	Phenolic, Wire Range #20 to #18 AWG, Spring Washer Mounting	<input type="checkbox"/> 974-2*			

\*Not CSA certified

For panel cutout dimensional data, see section O-Technical Reference

#### Icon Key

NAFTA Compliant - see page O-30