




GE
Lighting

26591 - 755

GE T3.25 (T3 1/4) - Low Voltage

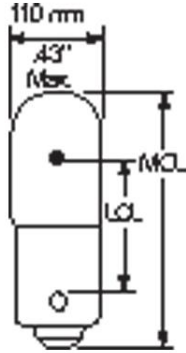

GENERAL CHARACTERISTICS

Lamp Type	Miniature - T & TL Shape
Bulb	T3.25 (T3 1/4)
Base	Miniature Bayonet (Ba9s)
Filament	C-2R
Rated Life	20000.0 hrs
Bulb Material	Hard glass
Atmosphere	Vacuum
Primary Application	Low Voltage

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	4.0
Nominal Initial Lumens per Watt	4
Mean Spherical Candlepower (MSCP)	0.33

ELECTRICAL CHARACTERISTICS

Wattage	1.0
Voltage	6.3

DIMENSIONS

Maximum Overall Length (MOL)	1.19 cm
Bulb Diameter (DIA)	0.406 cm
Light Center Length (LCL)	0.78 cm

PRODUCT INFORMATION


Product Code	26591
Description	755
ANSI Code	755
Standard Package	Case
Standard Package GTIN	10043168265918
Standard Package Quantity	50
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	50
UPC	043168265911



GE
Lighting

26591 - 755

GE T3.25 (T3 1/4) - Low Voltage

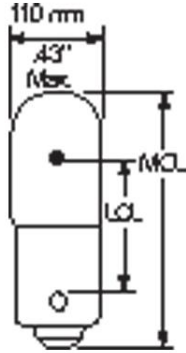

GENERAL CHARACTERISTICS

Lamp Type	Miniature - T & TL Shape
Bulb	T3.25 (T3 1/4)
Base	Miniature Bayonet (Ba9s)
Filament	C-2R
Rated Life	20000.0 hrs
Bulb Material	Hard glass
Atmosphere	Vacuum
Primary Application	Low Voltage

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	4.0
Nominal Initial Lumens per Watt	4
Mean Spherical Candlepower (MSCP)	0.33

ELECTRICAL CHARACTERISTICS

Wattage	1.0
Voltage	6.3

DIMENSIONS

Maximum Overall Length (MOL)	1.19 cm
Bulb Diameter (DIA)	0.406 cm
Light Center Length (LCL)	0.78 cm

PRODUCT INFORMATION

Product Code	26591
Description	755
ANSI Code	755
Standard Package	Case
Standard Package GTIN	10043168265918
Standard Package Quantity	50
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	50
UPC	043168265911