
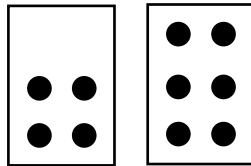


SWITCHES



Toggle Switches: Maintained Contact Single & Double Pole

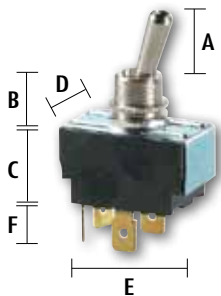

D.P.S.T D.P.D.T
Terminal Positions

CAT. NO.	CIRCUIT FUNCTIONS	POLES & THROWS	RATINGS			ACTUATOR STYLE	ACTUATOR MATERIAL	CONN. TYPE	STD. CTN. QTY.
			AMPS 125VAC	AMPS 250VAC	H.P 125-250VAC				
78220TS	ON-OFF	DPST	20	10	3/4	Bat	Brass/Nickel	Screws	5
78130TQ	ON-OFF	DPST	20	10	3/4	Bat	Brass/Nickel	0.250 Quikconnect	5
78090TQ	ON-ON	DPDT	15	10	—	Bat	Brass/Nickel	0.250 Quikconnect	5
78270TS	ON-ON	DPDT	20	10	1½@125.2@250	Bat	Brass/Nickel	Screws	5
78230TS	ON-OFF-ON	DPDT	10	20	1 1/2	Bat	Brass/Nickel	Screws	5
78240TS	OFF-ON	DPST	15	10	3/4	Bat	Brass/Nickel	Screws	5
78250TS	ON-OFF-ON	DPDT	15	10	3/4	Bat	Brass/Nickel	Screws	5
78260TS	ON-OFF-ON	DPDT	15	10	3/4	Bat	Brass/Nickel	Screws	5

 Dimensions (IN) A: 0.687 B: 0.465 C: 0.778 D: 0.750 E: 1.308 F: 0.422 THREAD: 15/32-32UNS-2A KEYWAY: 0.072 X 0.038

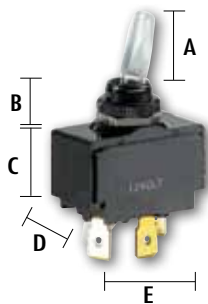

S.P.S.T
Terminal Positions

CAT. NO.	CIRCUIT FUNCTIONS	POLES & THROWS	RATINGS			ACTUATOR STYLE	ACTUATOR MATERIAL	CONN. TYPE	STD. CTN. QTY.
			AMPS 125VAC	AMPS 250VAC	H.P 125-250VAC				
78065TS	ON-OFF	SPST	6	3	—	Bat	Nickel	Screws	5
78040TQ	ON-OFF	SPST	15*	10*	3/4	Flat	Poly. (Red)**	0.250 Quikconnect	5

*Amperage and voltage are also valid for D.C. Rating /**Lighted toggle /Poly. = Polycarbonate

Dimensions (IN) A: 0.715 B: 0.379 C: 0.865 D: 0.750 E: 0.422 THREAD: 15/32-32UNS-2A KEYWAY: 0.072 X 0.038 DP