


# Tool Sets

Some projects are more complex than others and require a variety of tools to be used. For this reason, Klein has tool sets to assist professionals with these demanding projects.

For Professionals...  
Since 1857™

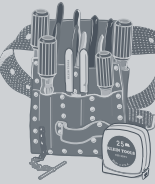

# Tool Sets

## 41-Piece Journeyman™ Tool Set

**JOURNEYMAN**



80141

Cat. No.	Set Contains	Weight (lbs.)
80141		29.8

Cat. No.	Description
BLK12	12-piece ball-end hex-key caddy set – inch
J203-6	Journeyman™ standard long-nose pliers
J203-8N	Journeyman™ heavy-duty long-nose pliers – side-cutting & stripping
J502-10	10" Journeyman™ pump pliers with 1-3/4" (44 mm) jaw capacity
D507-8	8" adjustable wrench – extra capacity
D507-12	12" adjustable wrench – extra capacity
600-1	1/4" keystone-tip cushion-grip screwdriver – 1-1/2" (40 mm) round-shank
600-4	1/4" keystone-tip cushion-grip screwdriver – 4" (102 mm) heavy-duty square-shank
601-3	3/16" cabinet-tip cushion-grip screwdriver – 3" (76 mm) round-shank
601-6	3/16" cabinet-tip cushion-grip screwdriver – 6" (152 mm) round-shank
602-6	5/16" keystone-tip cushion-grip screwdriver – 6" (152 mm) heavy-duty round-shank
603-1	No. 2 Phillips cushion-grip screwdriver – 1-1/2" (40 mm) round-shank
603-3	No. 1 Phillips cushion-grip screwdriver – 3" (76 mm) round-shank
603-4B	wire bending No. 2 Phillips cushion-grip screwdriver – 4" (102 mm) round-shank

Cat. No.	Description
605-6	1/4" cabinet-tip cushion-grip screwdriver – 6" (152 mm) heavy-duty round-shank
631	7-piece cushion-grip nut driver set (3/16", 1/4", 5/16", 11/32", 3/8", 7/16", 1/2")
650	cushion-grip scratch awl
662	No. 2 square-recess tip cushion-grip screwdriver – 4" (102 mm) round-shank
670-6	3/16" cabinet-tip cushion-grip screwdriver – Rapi-Drive®
93125	25' x 1" tape measure with magnetic tip
931-9RE	torpedo level - magnetic
J1005	Journeyman™ crimping/cutting tool – non-insulated and insulated connectors
K1412	Klein-Kurve® dual NM cable stripper/cutter
J2000-9NETP	Journeyman™ high-leverage side-cutting pliers – fish tape pulling
J2000-48	Journeyman™ high-leverage diagonal-cutting pliers – angled head
5003-18	18" 10-pocket canvas tool bag with leather bottom
5139	canvas zipper bag
11055	Klein-Kurve® wire stripper/cutter – 10-18 AWG solid & 12-20 AWG stranded
44133	Klein-Kurve® heavy-duty utility knife – quick change retractable blade
46037	cable-splicer's kit
56003	Steel Fish Tape - 125' L x 1/8" W
58889	padded adjustable shoulder strap
60053	standard protective eyewear
J63050	Journeyman™ high-leverage cable cutter
85191	conduit-fitting and reaming screwdriver

All dimensions are in inches and (millimeters).



[www.kleintools.com](http://www.kleintools.com)

See page 310 for additional information on warnings.



# Tool Sets

## 28-Piece Electrician Tool Set



80028

Cat. No.	Set Contains	Weight (lbs.)
80028		17.2

Cat. No.	Description
D203-8	heavy-duty long-nose pliers – side-cutting
D213-9NETP	high-leverage side-cutting pliers – fish tape pulling
D248-8	high-leverage diagonal-cutting pliers – angled head
D502-10	10" pump pliers with 1-3/4" (44 mm) jaw capacity
506-10	10" adjustable wrench – standard capacity
600-4	1/4" keystone-tip cushion-grip screwdriver – 4" (102 mm) heavy-duty square-shank
601-6	3/16" cabinet-tip cushion-grip screwdriver – 6" (152 mm) round-shank
602-6	5/16" keystone-tip cushion-grip screwdriver – 6" (152 mm) heavy-duty round-shank
603-4B	wire bending No. 2 Phillips cushion-grip screwdriver – 4" (102 mm) round-shank
605-6	1/4" cabinet-tip screwdriver – 6" (152 mm) heavy-duty round-shank
631	7-piece cushion-grip nut driver set (3/16", 1/4", 5/16", 11/32", 3/8", 7/16", 1/2")
662	No. 2 square-recess tip cushion-grip screwdriver – 4" (102 mm) round-shank
670-6	3/16" cabinet-tip cushion-grip screwdriver – Rapi-Drive®

Cat. No.	Description
93025	25' x 1" tape measure
930-9	magnetic torpedo level
1005	crimping/cutting tool – non-insulated and insulated connectors
5102-16	16" canvas tool bag
5139	canvas zipper bag
11045	wire stripper/cutter – 10-18 AWG solid wire
44100	utility knife – retractable blade
60056	frameless protective eyewear
85191	conduit-fitting and reaming screwdriver

All dimensions are in inches and (millimeters).



[www.kleintools.com](http://www.kleintools.com)

See page 310 for additional information on warnings.



# Tool Sets

## 18-Piece Journeyman™ Tool Set

**JOURNEYMAN**



80118

Cat. No.	Set Contains	Weight (lbs.)
80118		11.6

Cat. No.	Description
J203-8N	Journeyman™ heavy-duty long-nose pliers – side-cutting & stripping
J502-10	10" Journeyman™ pump pliers with 1-3/4" (44 mm) jaw capacity
D507-10	10" adjustable wrench – extra capacity
603-3	No. 1 Phillips cushion-grip screwdriver – 3" (76 mm) round-shank
603-4B	wire bending No. 2 Phillips cushion-grip screwdriver – 4" (102 mm) round-shank
605-4	1/4" cabinet-tip cushion-grip screwdriver – 4" (102 mm) heavy-duty round-shank
605-6	1/4" cabinet-tip cushion-grip screwdriver – 6" (152 mm) heavy-duty round-shank
630-1/4	1/4" cushion-grip nut driver – 3" (76 mm) shank
630-5/16	5/16" cushion-grip nut driver – 3" (76 mm) shank
662	No. 2 square-recess tip cushion-grip screwdriver – 4" (102 mm) round-shank

Cat. No.	Description
670-6	3/16" cabinet-tip cushion-grip screwdriver – Rapi-Driv™
93125	25' x 1" tape measure with magnetic tip
J2000-9NETP	Journeyman™ high-leverage side-cutting pliers – fish tape pulling
J2000-48	Journeyman™ high-leverage diagonal-cutting pliers – angled head
5165	10-pocket leather tool pouch
5705	Powerline™ web work belt
11055	Klein-Kurve™ wire stripper/cutter – 10-18 AWG solid & 12-20 AWG stranded
60053	standard protective eyewear

All dimensions are in inches and (millimeters).



[www.kleintools.com](http://www.kleintools.com)

See page 310 for additional information on warnings.

# Tool Sets

## 14-Piece Electrician Tool Set

Cat. No.	Set Contains	Weight (lbs.)
80014		9.6

Cat. No.	Description
D203-8	heavy-duty long-nose pliers – side-cutting
D213-9NETP	high-leverage side-cutting pliers – fish tape pulling
D248-8	high-leverage diagonal-cutting pliers – angled head
D502-10	10" pump pliers with 1-3/4" (44 mm) jaw capacity
603-3	No. 1 Phillips cushion-grip screwdriver – 3" (76 mm) round-shank
603-4B	wire bending No. 2 Phillips cushion-grip screwdriver – 4" (102 mm) round-shank
605-4	1/4" cabinet-tip cushion-grip screwdriver – 4" (102 mm) heavy-duty round-shank
605-6	1/4" cabinet-tip cushion-grip screwdriver – 6" (152 mm) heavy-duty round-shank
670-6	3/16" cabinet-tip cushion-grip screwdriver – Rapi-Drive™
93025	25' x 1" tape measure
5164	8-pocket leather tool pouch
5225	adjustable web tool belt
11045	wire stripper/cutter – 10-18 AWG solid wire
60056	frameless protective eyewear



80014

## 12-Piece Electrician Tool Set

Cat. No.	Set Contains	Weight (lbs.)
5300		6.82

Cat. No.	Description
5166	7-pocket leather tool pouch
5225	adjustable web belt
603-3	No. 1 Phillips cushion-grip screwdriver – 3" (76 mm) round-shank
603-4	No. 2 Phillips cushion-grip screwdriver – 4" (102 mm) round-shank
605-4	1/4" cabinet-tip cushion-grip screwdriver – 4" (102 mm) heavy-duty round-shank
605-6	1/4" cabinet-tip cushion-grip screwdriver – 6" (152 mm) heavy-duty round-shank
11045	wire stripper/cutter – 10-18 AWG solid wire
D248-8	high-leverage diagonal-cutting pliers – angled head
D203-8	heavy-duty long-nose pliers – side-cutting
D213-9NETP	high-leverage side-cutting pliers – fish tape pulling
D502-10	pump pliers with 1-3/4" (44 mm) jaw capacity
928-25HV	high-visibility power-return measuring tape



5300

All dimensions are in inches and (millimeters).



[www.kleintools.com](http://www.kleintools.com)

See page 310 for additional information on warnings.

# Tool Sets

## 12-Piece Electrician Tool Set



92003

Cat. No.	Set Contains	Weight (lbs.)
92003		17
Cat. No.	Description	
D213-9NETP	9" high-leverage side-cutting pliers – fish tape pulling	
D248-8	8" high-leverage diagonal-cutting pliers	
D203-8	8" heavy duty long-nose pliers – side-cutting	
D502-10	10" pump pliers	
11045	wire stripper/cutter	
93275	metric/english tape measure with magnetic tip	
603-4	No. 2 profilated Phillips tip screwdriver – 4" round shank	
605-4	1/4" cabinet tip cushion-grip screwdriver – 4" heavy duty round shank	
661	No.1 square-recess tip screwdriver – 4" round shank	
662	No. 2 square-recess tip cushion-grip screwdriver – 4" (102 mm) round-shank	
5719	18 Pocket Tool Pouch	
5705	Powerline™ web work belt	

**WARNING:** Do NOT open the tape measure case. Spring motor is under tension, and opening may cause injury.



All dimensions are in inches and (millimeters).

[www.kleintools.com](http://www.kleintools.com)

See page 310 for additional information on warnings.