


90° Zinc

Images

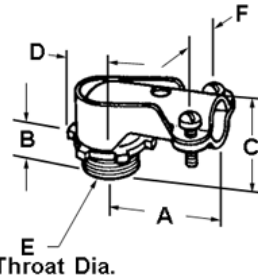

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-5/8
Dimension B in Inches: 1/2
Dimension C in Inches: 1-5/8
Dimension D in Inches: 1/2
Dimension E in Inches: 5/8
Dimension F in Inches: 1-3/4

Application

90 Degrees connector recommended cable types used to connect flexible metal conduit to box or enclosure. Diameter for (.75" 0 min) to (.875" 0 max)

Product Information

Material: Zinc Die Cast
Finish: Ball burnished, mirror smooth

Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E20534
UL Standard:	UL-514B
UNSPSC:	39121419

Catalog ID: 804-DC2

UPC Number: 781747158048

Description: Connector, 90 Degrees, Zinc Die Cast, Flex Size 1/2 Inch

Application: 90 Degrees connector recommended cable types used to connect flexible metal conduit to box or enclosure. Diameter for (.75" 0 min) to (.875" 0 max)

Trade Size: 1/2"

Country of Manufacture: USA

Std Pkg Qty: 100

Unit Qty: 25