



CONDUIT TO T-GRID CLIP, 1/2", 3/4" EMT, 0.709"–1.181" OD

CATALOG NUMBER

812MATA



FEATURES

Provides a method of securing conduit above acoustical tee bar

No tools required for installation

Eliminates need for offset bending conduit

PRODUCT ATTRIBUTES

Material: Spring Steel

Finish: nVent CADDY Armour

EMT Conduit Size: 1/2";3/4"


Outer Diameter (OD): 0.710" - 1.18"

ADDITIONAL PRODUCT DETAILS

No load rating, for positioning only.

Additional support required per NEC® 300.11.

DIAGRAMS

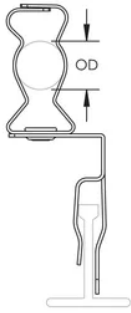

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**
TRACER



CONDUIT TO T-GRID CLIP, 1/2", 3/4" EMT, 0.709"–1.181" OD

CATALOG NUMBER

812MATA



FEATURES

Provides a method of securing conduit above acoustical tee bar

No tools required for installation

Eliminates need for offset bending conduit

PRODUCT ATTRIBUTES

Material: Spring Steel

Finish: nVent CADDY Armour

EMT Conduit Size: 1/2";3/4"


Outer Diameter (OD): 0.710" - 1.18"

ADDITIONAL PRODUCT DETAILS

No load rating, for positioning only.

Additional support required per NEC® 300.11.

DIAGRAMS

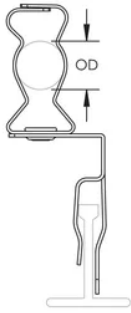

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



nVent.com

Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF

TRACER