



OmniCONN™ Compression RCA and F Connectors



OmniCONN™
Compression RCA Connectors

OmniCONN™ RG-59 and RG-6 Compression RCA Connectors

- **OmniCONN™ RCA compression connectors install easily onto standard RG 6 and RG 59 cable**
- **Constructed of nickel plated brass and gold plated head**
- **75 ohm nominal impedance**
- **Bandwidth up to 3 GHz**
- **Compatible with 30-603 and 30-793 OmniSEAL™ compression tools**



OmniCONN™
Compression F Connectors

OmniCONN™ RG-6 & RG-6 Quad Compression F Connectors

- **OmniCONN™ F compression connectors install easily onto standard RG 6 and RG 6Quad cables**
- **Non corrosive nickel plated brass body and polycarbonate bushing**
- **Delrin/Nylon adapter sleeve and o-ring provide double protection for a watertight seal**
- **Free spinning hex nut for ease of installation onto all 7/16" ports**
- **75 ohm nominal impedance**
- **Bandwidth up to 3 GHz**

IDEAL DataComm

CUT

STRIP

TERMINATE

TEST

CERTIFY



OmniCONN™ Compression RCA and F Connectors

OmniCONN™ F Connectors



Specifications

- Bandwidth: 0 MHz– 3 GHz
- Impedance: 75 Ohms (nominal)
- Return Loss: Minimum -30 dB @ 3 GHz
- Operating Temperature Range: -40° F to +140° F
- Meets SCTE Cable Retention guidelines

Construction

- Free spinning hex nut for ease of installation (7/16")
- Delrin /Nylon adapter sleeve and inner 'O' ring provide double protection for a watertight seal
- Nut body and mandrel made of All-brass construction, nickel plated for superior corrosion resistance

Cat. No.		Description
4 pack	Jar of 50	
89-017	89-044	OmniCONN™ RG-6 Compression F Connectors
89-018	89-045	OmniCONN™ RG-6 Quad Compression F Connectors

OmniCONN™ RCA Connectors



Specifications

- Bandwidth: 0 MHz– 3 GHz
- Impedance: 75 Ohms (nominal)
- Return Loss: Minimum -30 dB @ 3 GHz
- Operating Temperature Range: -40° F to +140° F
- Meets SCTE Cable Retention guidelines

Construction

- Easily installs onto RG 6 and RG59 cable
- HDPE adapter sleeve and inner 'O' ring provide double protection for a watertight seal
- All Brass - Nickel Plated body Construction and gold plated head

Cat. No.		Description
10 pack	Jar of 35	
89-572	89-570	OmniCONN™ RG-59 Compression RCA Connectors
89-582	89-580	OmniCONN™ RG-6 Compression RCA Connectors

OmniSEAL Pro 30-603




OmniSEAL Pro XL 30-793 – compresses BNC compression connectors

OmniSEAL™ Pro and Pro XL Compression Tools

The new IDEAL OmniSEAL™ compression tool now offers additional features and increased connector compatibility in a smaller, more compact tool designed to meet the demands of the professional installer.

Cat. No.	Description
30-793	OmniSEAL™ Pro XL Compression Tool
30-603	OmniSEAL™ Pro Compression Tool

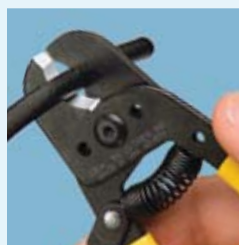

45-074 Data T®-Cutter

- Cuts round communication cable and maintains cable geometry for better cable performance
- Steel reinforced center conductor can be trimmed with bolt cutting holes
- Cushioned comfort grip handles
- Locking latch keeps tool closed in pouch



45-603 Coax/UTP Stripper

- Features two active strip cartridges for all RG59, RG6, RG6 Quad and UTP cables
- Push on ring for easy cable into connector insertion
- Rotates easily around finger
- No blade depth adjustments required

IDEAL INDUSTRIES, INC.

Becker Place, Sycamore, IL 60178, USA / 815-895-5181 • 800-435-0705 in USA

International offices:

Australia • Brazil • Canada • China • Germany • Mexico • UK

For complete sales office contact information, visit us at:

www.idealindustries.com