

Project:	Type:	Prepared By:	Date:
-----------------	--------------	---------------------	--------------



Features and Benefits

- Energy efficient replacement for incandescent and halogen lamps
- Constructed from durable plastic which lowers risk of breakage
- Rated for use in enclosed and open fixtures in dry or damp locations (>15W A19 is Open fixture rated)
- Frosted lens produces smooth diffuse light
- Longer lifespan compared to legacy equivalents minimizes replacement and maintenance costs
- ENERGY STAR Compliant
- Dimmable with common dimmer types (check compatibility list)

Technical Specifications		
Performance	L70 Lifespan:	Other
Product Type: A-Line	15,000 Hours	Equivalency: 60W Incandescent
Input Wattage: 10W	Dimmable: Yes, down to 10%	Warranty (Years): RAB warrants that our LED products will be free from defects in materials and workmanship for a period of three (3) years from the date of delivery to the end user, including coverage of light output, color stability, driver performance and fixture finish. RAB's warranty is subject to all terms and conditions found at rablighting.com/warranty .
Typical Lumen Output: 800	Construction	Electrical
Efficacy: 80 lm/W	Bulb Shape: A19	Power Factor: ≥0.7
Color Temperature: 4000K Cool White	Base Type: E26	Operating Temperature: -20°C - 45°C
CRI: 80	Beam Angle: 230°	Input Voltage: 120V
	For Use Outdoors in Open Fixtures: No	

Technical Specifications (continued)

Electrical

Operating Frequency:

60 Hz

Electrical Characteristics

Input Current @ 120V:

101mA

Compliance

UL Listed:

Yes

ENERGY STAR V2.0:

This product is ENERGY STAR® Version 2.0 Certified

Energy Star ID:

2357503


CEC Status:

Not lawful for sale in California

Case and Pallet Dimensions

	QTY	LENGTH (in)	WIDTH (in)	HEIGHT (in)
CASE	12	15.4	5.2	4.9
PALLET	2268	47.2	39.4	45.7

Dimension

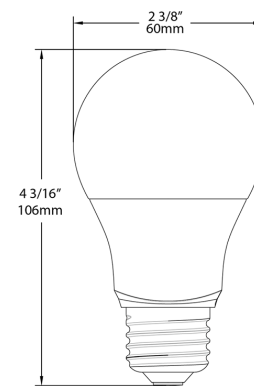

Light Distribution

