




## NVENT CADDY ALL-IN-ONE STUD-MOUNTED WITH ADJUSTABLE MUD RING, 2 GANG, 5/8"–1 1/2" DRYWALL, 3 5/8"

### CATALOG NUMBER

**A1SFV2G**

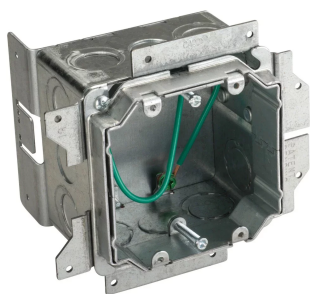

### CERTIFICATIONS



### FEATURES

Adjustable mud ring accommodates various thicknesses of drywall

Can be adjusted after the installation of drywall

Box remains fixed in place when mud ring is removed

Includes multiple knockouts on each side of the box

Assemblies keyed for precise alignment when installed on both sides of a stud

### PRODUCT ATTRIBUTES

Material: Steel

Finish: Pregalvanized

Knockout Sizes: (8) 1/2", 3/4";(3) 1/2"

Gang: 2

Ground Wire Included: Yes

Back Plate Pre-assembled: Yes

Box Volume: 32.8in<sup>3</sup>

Drywall Thickness: 5/8" - 1 1/2"

Depth (D): 3 5/8"


A: 5 3/4"

B: 5 1/8"

ADDITIONAL PRODUCT DETAILS

Ground wire pigtail is 10".

DIAGRAMS

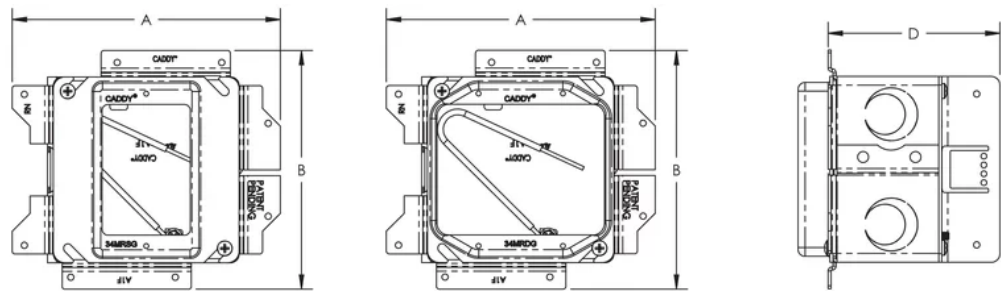

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500




Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**



## NVENT CADDY ALL-IN-ONE STUD-MOUNTED WITH ADJUSTABLE MUD RING, 2 GANG, 5/8"–1 1/2" DRYWALL, 3 5/8"

### CATALOG NUMBER

**A1SFV2G**

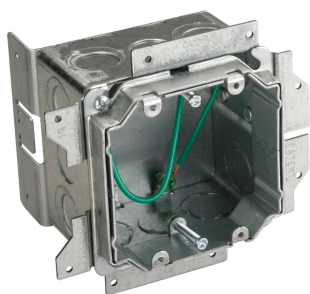

### CERTIFICATIONS



### FEATURES

Adjustable mud ring accommodates various thicknesses of drywall

Can be adjusted after the installation of drywall

Box remains fixed in place when mud ring is removed

Includes multiple knockouts on each side of the box

Assemblies keyed for precise alignment when installed on both sides of a stud

### PRODUCT ATTRIBUTES

Material: Steel

Finish: Pregalvanized

Knockout Sizes: (8) 1/2", 3/4";(3) 1/2"

Gang: 2


Ground Wire Included: Yes

Back Plate Pre-assembled: Yes
Box Volume: 32.8in <sup>3</sup>
Drywall Thickness: 5/8" - 1 1/2"
Depth (D): 3 5/8"
A: 5 3/4"
B: 5 1/8"

### ADDITIONAL PRODUCT DETAILS

Ground wire pigtail is 10".

### DIAGRAMS

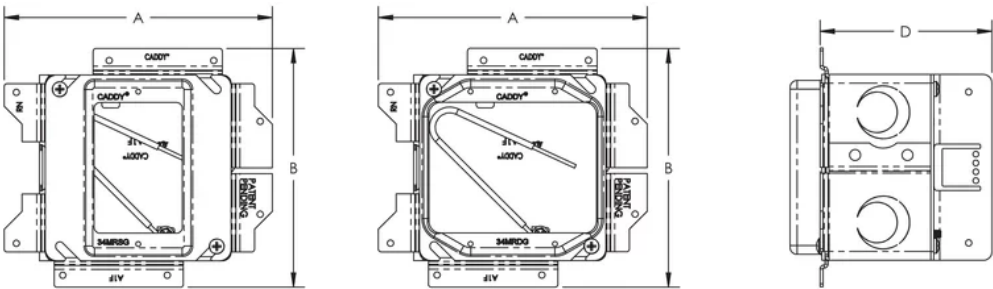

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

<b>North America</b> +1.800.753.9221 Option 1 – Customer Care Option 2 – Technical Support	<b>Europe</b> Netherlands: +31 800-0200135 France: +33 800 901 793	<b>Europe</b> Germany: 800 1890272 Other Countries: +31 13 5835404	<b>APAC</b> Shanghai: + 86 21 2412 1618/19 Sydney: +61 2 9751 8500
-----------------------------------------------------------------------------------------------------	--------------------------------------------------------------------------------	--------------------------------------------------------------------------------	--------------------------------------------------------------------------------