

BURNDY Catalog Number
UPC Number
Description
Status

AMS0
 7818102410111
 1/0-14 DUAL RATED SPLICE
 Active

Web Use
 BURNDY Product Line

Width (in)
 Length (in)
 Hex Size
 H1

Dimensional
 0.75
 1.91
 Slot
 0.75

Number of Screws

General

2
 Aluminum Mechanical Splice, 1/0-14 AWG, 7/16" Screw Dia, 2 Screws, Al/Cu Rated, Tin Plated

Product Description

Conductor(s)

Aluminum Size (Range)
 Copper Solid Size (Range)
 Copper Stranded (Range)

12 AWG-1/0 AWG
 12 AWG-1/0 AWG
 14 AWG-1/0

Installation Torque
 Type of Plating
 Connector Type
 Plated (Yes or No)
 Product Material

Physical

50
 Tin
 Splice, Reducer
 Y
 Aluminum

Rated for Direct Burial
 UL Listed
 CSA Certified
 ROHS Compatible
 Industry Standards

Approvals / Certifications

N
 Y
 Y
 Exempt
 UL467

Documentation

For further technical assistance, please contact us

 

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175

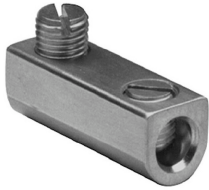

BURNDY Catalog Number
UPC Number
Description
Status

AMS0
 7818102410111
 1/0-14 DUAL RATED SPLICE
 Active

Web Use
 BURNDY Product Line

Width (in)
 Length (in)
 Hex Size
 H1

Dimensional
 0.75
 1.91
 Slot
 0.75

Number of Screws

General

2
 Aluminum Mechanical Splice, 1/0-14 AWG, 7/16" Screw Dia, 2 Screws, Al/Cu Rated, Tin Plated

Product Description

Conductor(s)

Aluminum Size (Range)
 Copper Solid Size (Range)
 Copper Stranded (Range)

12 AWG-1/0 AWG
 12 AWG-1/0 AWG
 14 AWG-1/0

Installation Torque
 Type of Plating
 Connector Type
 Plated (Yes or No)
 Product Material

Physical

50
 Tin
 Splice, Reducer
 Y
 Aluminum

Rated for Direct Burial
 UL Listed
 CSA Certified
 ROHS Compatible
 Industry Standards

Approvals / Certifications

N
 Y
 Y
 Exempt
 UL467

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175