


# Eaton BRP20L200

Catalog Number: BRP20L200

Eaton Eaton BR main lug loadcenter,Main lug only,200 A,X3,Aluminum, NEMA 1,Metallic,10kAIC,CSR2200,NEMA1,40 Circuits,Twenty-four pole,20 Spaces,Two hots,a neutral,and a ground,Single-phase,Type BR 1-inch breakers,120/240V,#1–300 kcmil

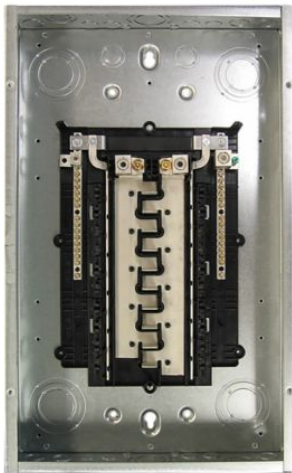

## General specifications

|                              |                      |
|------------------------------|----------------------|
| Product Name                 | Catalog Number       |
| Eaton BR main lug loadcenter | BRP20L200            |
| UPC                          | Product Length/Depth |
| 786689053260                 | 23 in                |
| Product Height               | Product Width        |
| 3.88 in                      | 14.31 in             |
| Product Weight               | Warranty             |
| 21 lb                        | 10 year              |
| Certifications               |                      |
| UL 50                        |                      |
| UL 67                        |                      |

## defaultTaxonomyAttributeLabel

### Type

MLO

### Amperage Rating

200 A

### Bus material

Aluminum

### Cover

Cover included

### Main circuit breaker

CSR2200

### Number of circuits

40

### Number Of Poles

Single-pole

### Number of spaces

20

### Phase

Single-phase

### Used with

Type BR 1-inch breakers

### Voltage rating

120/240V

### Box size

X3

### Enclosure

NEMA 1

### Enclosure material

Metallic

### Interrupt rating

10 kAIC

### NEMA rating

NEMA 1

### Number of wires

Two hots, neutral and ground

## Resources

### Brochures

[Loadcenters and Circuit Breakers](#)

### Specifications and datasheets

[Eaton Specification Sheet - BRP20L200](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are  
property of their respective  
owners.




[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)

# Eaton BRP20L200

Catalog Number: BRP20L200

Eaton Eaton BR main lug loadcenter,Main lug only,200 A,X3,Aluminum, NEMA 1,Metallic,10kAIC,CSR2200,NEMA1,40 Circuits,Twenty-four pole,20 Spaces,Two hots,a neutral,and a ground,Single-phase,Type BR 1-inch breakers,120/240V,#1–300 kcmil

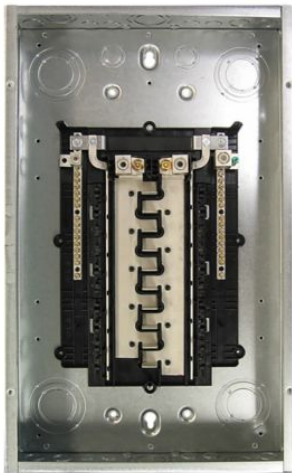

## General specifications

|                              |                      |
|------------------------------|----------------------|
| Product Name                 | Catalog Number       |
| Eaton BR main lug loadcenter | BRP20L200            |
| UPC                          | Product Length/Depth |
| 786689053260                 | 23 in                |
| Product Height               | Product Width        |
| 3.88 in                      | 14.31 in             |
| Product Weight               | Warranty             |
| 21 lb                        | 10 year              |
| Certifications               |                      |
| UL 50                        |                      |
| UL 67                        |                      |

## defaultTaxonomyAttributeLabel

### Type

MLO

### Amperage Rating

200 A

### Bus material

Aluminum

### Cover

Cover included

### Main circuit breaker

CSR2200

### Number of circuits

40

### Number Of Poles

Single-pole

### Number of spaces

20

### Phase

Single-phase

### Used with

Type BR 1-inch breakers

### Voltage rating

120/240V

### Box size

X3

### Enclosure

NEMA 1

### Enclosure material

Metallic

### Interrupt rating

10 kAIC

### NEMA rating

NEMA 1

### Number of wires

Two hots, neutral and ground

## Resources

### Brochures

[Loadcenters and Circuit Breakers](#)

### Specifications and datasheets

[Eaton Specification Sheet - BRP20L200](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are  
property of their respective  
owners.



[Eaton.com/socialmedia](https://Eaton.com/socialmedia)