


Eaton C25DND240A

Catalog Number: C25DND240A

Eaton definite purpose contactor, Quick, 40A, 110-120 Vac, 50/60 Hz, Open with metal mounting plate, 15-50A, two- and three-pole, 40A, Contactor, Two-pole, 50A, Screw/pressure plate and quick connect terminals (side-by-side), Non-reversing

General specifications

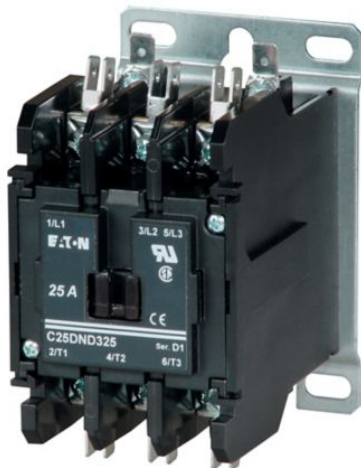

Product Name	Catalog Number
Eaton definite purpose contactor	C25DND240A
UPC	Product Length/Depth
782116300389	3.35 in
Product Height	Product Width
3.75 in	2.4 in
Product Weight	Warranty
1.19 lb	1 year
Compliances	Certifications
RoHS Compliant	CSA Certified
	UL Recognized

defaultTaxonomyAttributeLabel

Amperage Rating

40A

Number Of Poles

Two-pole

Type

Non-reversing

Coil

110-120 Vac, 50/60 Hz

Enclosure

Open with metal mounting plate

Frame size

15-50 A, two-pole and three-pole

Inductive full load

40 A

Model

Contactors

Resistive load

50 A

Terminals

Screw/pressure plate and quick connect terminals (side-by-side)

Connection

Quick

Resources

Catalogs

[Eaton's Volume 5—Motor Control and Protection](#)

Specifications and datasheets

[Eaton Specification Sheet - C25DND240A](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)