


# Eaton C25DNF240T

Catalog Number: C25DNF240T

Eaton definite purpose contactor, Mounting plate, Quick, Quick connect , 12 Vac, 50/60 Hz, Open with metal mounting plate, 15-50A, two- and 3P, 40A, Contactor, Two-pole, Global listed, D1, Box lugs (posidrive setscrew), Non-reversing

## General specifications

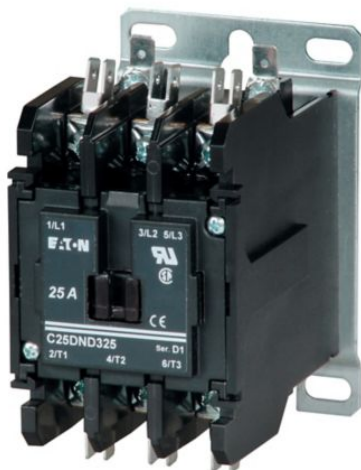

Product Name	Catalog Number
Eaton definite purpose contactor	C25DNF240T
UPC	Product Length/Depth
782116300426	3.35 in
Product Height	Product Width
3.75 in	2.4 in
Product Weight	Warranty
1.19 lb	1 year
Compliances	Certifications
RoHS Compliant	CSA Certified
	UL Recognized
	UL Listed file E1491 (Guide Number NLDX2)

## defaultTaxonomyAttributeLabel

### Amperage Rating

40A

### Number Of Poles

Two-pole

### Options

Global listed

### Type

Non-reversing

### Auxiliary contacts

Quick connect (side-by-side)

### Coil

120 Vdc

### Coil voltage

50/60 Hz

### Enclosure

Open with metal mounting plate

### Frame size

15-50 A, two-pole and three-pole

### Inductive full load

50 A

### Model

Contactor

### Resistive load

50 A

### Series

D1

### Terminals

Box lugs (posidrive setscrew)

### Connection

Quick

## Resources

### Catalogs

Eaton's Volume 5—Motor Control and Protection

### Drawings

C25DNF2 AutoCAD 2D Footprint (mm)

C25DNF2 2D PDF

C25DNF2 3D Inventor

C25DNF2 AutoCAD 2D Footprint

C25DNF2 3D Model Xchange

C25DNF2 2D Drawing Xchange

### Specifications and datasheets

Eaton Specification Sheet - C25DNF240T



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)