

# Eaton CHP42E225X7

Catalog Number: CHP42E225X7

Eaton CH PON 3/4-in Eaton CH loadcenter, 225A, convertible, lugs inst, 42 spaces, NEMA 1, Copper bus, Top/bottom feed, X7, Single phase, three wire



## General specifications

<b>Product Name</b>	<b>Catalog Number</b>
Eaton CH convertible loadcenter	CHP42E225X7
<b>UPC</b>	<b>Product Length/Depth</b>
786679189740	37 in
<b>Product Height</b>	<b>Product Width</b>
3.88 in	14.31 in
<b>Product Weight</b>	<b>Warranty</b>
20.5 lb	Limited lifetime
<b>Certifications</b>	<b>Catalog Notes</b>
UL 50 UL 67	Purchase Size X7 Cover Separately

## defaultTaxonomyAttributeLabel

### Type

Convertible, Main Lugs Installed

### Amperage Rating

225 A

### Bus material

Copper

### Cover

X7

### Feed type

Top/bottom

### Number of circuits

42

### Number of spaces

42

### Phase

Single-phase

### Voltage rating

120/240 V

### Box size

X7

### Enclosure

NEMA 1

### Enclosure material

Metallic

### Interrupt rating

25 kAIC

### Number of wires

3

## Resources

### Brochures

[Loadcenters and Circuit Breakers](#)

### Multimedia

[AFCI Educational Video](#)

### Specifications and datasheets

[Eaton Specification Sheet - CHP42E225X7](#)

### Warranty guides

[Eaton type CH circuit breaker limited warranty June 2024](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.




[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)

# Eaton CHP42E225X7

Catalog Number: CHP42E225X7

Eaton CH PON 3/4-in Eaton CH loadcenter, 225A, convertible, lugs inst, 42 spaces, NEMA 1, Copper bus, Top/bottom feed, X7, Single phase, three wire

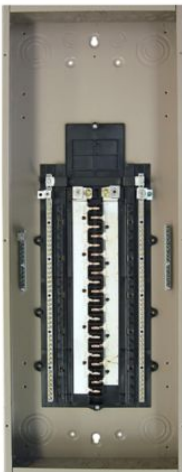

## General specifications

<b>Product Name</b>	<b>Catalog Number</b>
Eaton CH convertible loadcenter	CHP42E225X7
<b>UPC</b>	<b>Product Length/Depth</b>
786679189740	37 in
<b>Product Height</b>	<b>Product Width</b>
3.88 in	14.31 in
<b>Product Weight</b>	<b>Warranty</b>
20.5 lb	Limited lifetime
<b>Certifications</b>	<b>Catalog Notes</b>
UL 50 UL 67	Purchase Size X7 Cover Separately

## defaultTaxonomyAttributeLabel

### Type

Convertible, Main Lugs Installed

### Amperage Rating

225 A

### Bus material

Copper

### Cover

X7

### Feed type

Top/bottom

### Number of circuits

42

### Number of spaces

42

### Phase

Single-phase

### Voltage rating

120/240 V

### Box size

X7

### Enclosure

NEMA 1

### Enclosure material

Metallic

### Interrupt rating

25 kAIC

### Number of wires

3

## Resources

### Brochures

[Loadcenters and Circuit Breakers](#)

### Multimedia

[AFCI Educational Video](#)

### Specifications and datasheets

[Eaton Specification Sheet - CHP42E225X7](#)

### Warranty guides

[Eaton type CH circuit breaker limited warranty June 2024](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://Eaton.com/socialmedia)