

## DESCRIPTION

The Caretaker™ LED area luminaire incorporates durability, long life, and unmatched performance in a package that is ideal for a wide variety of applications. The unique universal mounting bracket allows quick and easy installation whether it is wall mounted security lighting, residential street lighting, perimeter area lighting, parking areas, loading platforms, boat docks, access drives or pathways. Designed for years of worry-free illumination, the Caretaker luminaire is UL/cUL listed for wet locations, has a heavy-duty die-cast aluminum housing and includes an integrated 6kV surge protection device.

<b>Catalog #</b>		<b>Type</b>	
<b>Project</b>			
<b>Comments</b>		<b>Date</b>	
<b>Prepared by</b>			

## SPECIFICATION FEATURES

### Construction

Single heavy-duty die-cast aluminum housing. Access via stamped aluminum door for ease of installation and maintenance. Corrosion resistant hardware. Spun aluminum shield for full cutoff.

### Optics

Precision molded optics are designed to shape the distribution, maximize efficiency, and application coverage. Available in three lumen packages with standard 4000K CCT with a minimum 70 CRI. The Type V round symmetric distribution creates a consistent, even distribution replacing up to 250W metal halide. Optic is IP66 rated.

### Electrical

LED driver is standard universal voltage and 0-10V dimming with integrated 6kV surge protection. A NEMA 3-PIN photocontrol receptacle and twist-lock photocontrol for dusk-to-dawn operation are provided standard. The Caretaker is designed for efficient thermal management; heat is transferred away from the LEDs for optimal efficiency, light output, and life. Lumen maintenance of 90% at 60,000 hours.

### Mounting

The Caretaker luminaire is supplied with a universal mounting bracket for either wall or wood pole mounting and an integral two-bolt slipfitter for mounting on 1-1/4" to 2" standard pipe (1-5/8" to 2-3/8" O.D.).

### Finish

Standard natural aluminum finish.

### Warranty

Five-year warranty.




## CTKR CARETAKER LED

Solid State LED


AREA LUMINAIRE  
DUSK-TO-DAWN

## DIMENSIONS

### Full Cutoff (Standard)

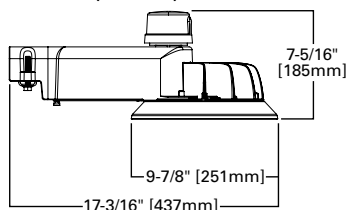


### Small Acrylic Refractor

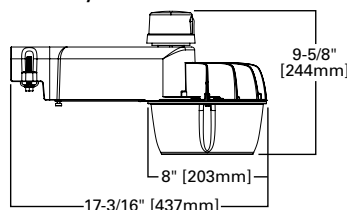


## WALL / POLE MOUNTING BRACKET (INCLUDED)

### Wall Mount / Square Pole Mount

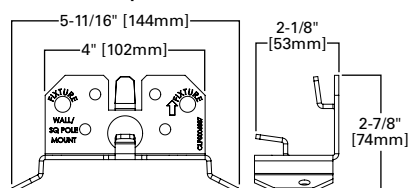

### Pole Mount

 

## CERTIFICATION DATA

UL/cUL Wet Location Listed  
IP66 Rated (Optic)  
LM79/LM80 Compliant  
3G Vibration Rated  
RoHS Compliant  
ISO 9001  
DesignLights Consortium® Qualified\*

## ENERGY DATA

Electronic LED Driver  
> 0.9 Power Factor  
< 20% Total Harmonic Distortion  
120-277V, 50/60Hz  
-40°C Minimum Ambient Temperature Rating  
+40°C Maximum Ambient Temperature Rating

## EPA

Effective Projected Area: (Sq. Ft.)  
Full Cutoff: 0.52  
Small Acrylic Refractor: 0.58

## SHIPPING DATA

Approximate Net Weight: 7 lbs. (3.2 kgs.)

**POWER AND LUMENS**

<b>Light Engine</b>		<b>1B</b>	<b>2B</b>	<b>3B</b>
<b>Power (Watts)</b>		29W	50W	71W
<b>Input Current @ 120V (A)</b>		0.25	0.42	0.60
<b>Input Current @ 277V (A)</b>		0.11	0.17	0.26
<b>Standard</b>	Lumens	4,515	7,110	9,741
	BUG Rating	B3-U0-G1	B3-U0-G2	B4-U0-G2
<b>Small Acrylic Refractor</b>	Lumens	4,435	6,983	9,567
	BUG Rating	B3-U3-G2	B3-U3-G2	B4-U3-G3

**LUMEN MULTIPLIER**

<b>Ambient Temperature</b>	<b>Lumen Multiplier</b>
10°C	1.02
15°C	1.01
25°C	1.00
40°C	0.99

**LUMEN MAINTENANCE**

<b>Ambient Temperature</b>	<b>TM-21 Lumen Maintenance (60,000 Hours)</b>	<b>Theoretical L70 (Hours)</b>
<b>CTKRV1B, CTKRV2B</b>		
25°C	90.72%	>220,000
40°C	90.72%	>220,000
<b>CTKRV3B</b>		
25°C	90.72%	>220,000
40°C	87.70%	>162,000

**ORDERING INFORMATION**

<b>Stock Number</b>	<b>Accessories (Order Separately)</b>
CTKRV1B=Caretaker 29W, 4500lm, UNV, Dimming, Photocontrol CTKRV2B=Caretaker 50W, 7100lm, UNV, Dimming, Photocontrol CTKRV3B=Caretaker 71W, 9700lm, UNV, Dimming, Photocontrol	SR-CARETAKER=Small Acrylic Refractor RMRROA5=ANSI/NEMA Acrylic Refractor Assembly DS-HSS-CRTK2=Drop Shield House Side Shield OA/RA1013=Shorting Cap