


# DURAFLOOD 100

## LED FLOOD LIGHT (100 WATT)

250 MH Replacement



Lumens	9,000
CCT	3000-3500K, 4000-4500K, 6000-6500K
CRI	> 75
Beam Angle	120°
Operating Voltage	100 - 277 VAC
Power Consumption	100W
Driver	Mean Well
LED Source	Bridgelux
Lifespan	> 50,000 Hours
IP Grade	IP65
Body Construction	Aluminum & Toughened Glass
Dimensions	11.22" x 15.12" x 7.28"
Weight	12.35 lbs

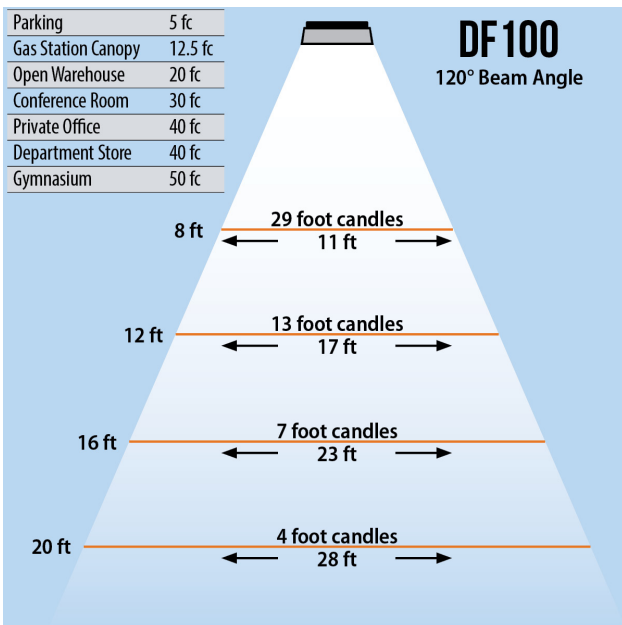

### ORDER CODE Example: DF100-BRZ-6K

Fixture	Finish	CCT
DF100- Trunnion	BRZ- Bronze	6K- 6000K
		4K- 4000K
		3K- 3000K

## DURAFLOOD 100




## LED FLOOD LIGHT (100 WATT)

250 MH Replacement



Lumens	9,000
CCT	3000-3500K, 4000-4500K, 6000-6500K
CRI	> 75
Beam Angle	120°
Operating Voltage	100 - 277 VAC
Power Consumption	100W
Driver	Mean Well
LED Source	Bridgelux
Lifespan	> 50,000 Hours
IP Grade	IP65
Body Construction	Aluminum & Toughened Glass
Dimensions	11.22" x 15.12" x 7.28"
Weight	12.35 lbs

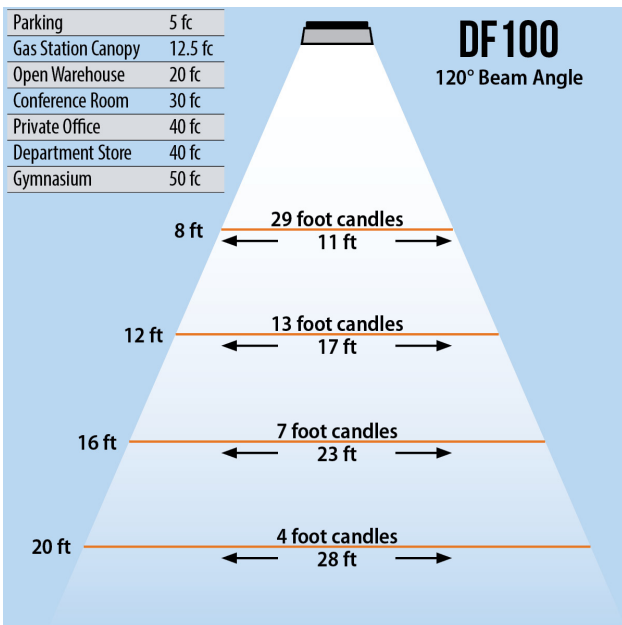

## ORDER CODE Example: DF100-BRZ-6K

Fixture	Finish	CCT
DF100- Trunnion	BRZ- Bronze	6K- 6000K
		4K- 4000K
		3K- 3000K