

# DURAFLOOD 10

## LED FLOOD LIGHT (10 WATT)

60W PAR 38 Replacement




Trunion Mount

Knuckle Mount



Lumens	900
CCT	3000-3500K, 6000-6500K
CRI	> 75
Beam Angle	120°
Operating Voltage	100 - 240 VAC
Power Consumption	10W
LED Source	Bridgelux
Lifespan	> 50,000 Hours
IP Grade	IP65
Body Construction	Aluminum & Toughened Glass
Dimensions	4.53" x 2.60" x 4.13"
Weight	1 lbs

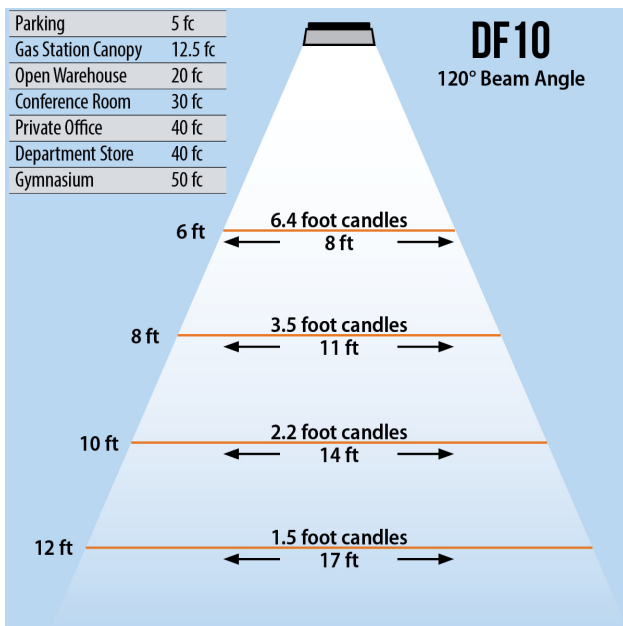

### ORDER CODE Example DF10-BRZ-10W120D6K

Fixture	Finish	Beam Angle	CCT
DF10 - Trunion	BRZ - Bronze	10W120D - 120°	6K - 6000K
DF10KM - Knuckle			3K - 3000K

# DURAFLOOD 10

## LED FLOOD LIGHT (10 WATT)

60W PAR 38 Replacement




Trunion Mount

Knuckle Mount



Lumens	900
CCT	3000-3500K, 6000-6500K
CRI	> 75
Beam Angle	120°
Operating Voltage	100 - 240 VAC
Power Consumption	10W
LED Source	Bridgelux
Lifespan	> 50,000 Hours
IP Grade	IP65
Body Construction	Aluminum & Toughened Glass
Dimensions	4.53" x 2.60" x 4.13"
Weight	1 lbs

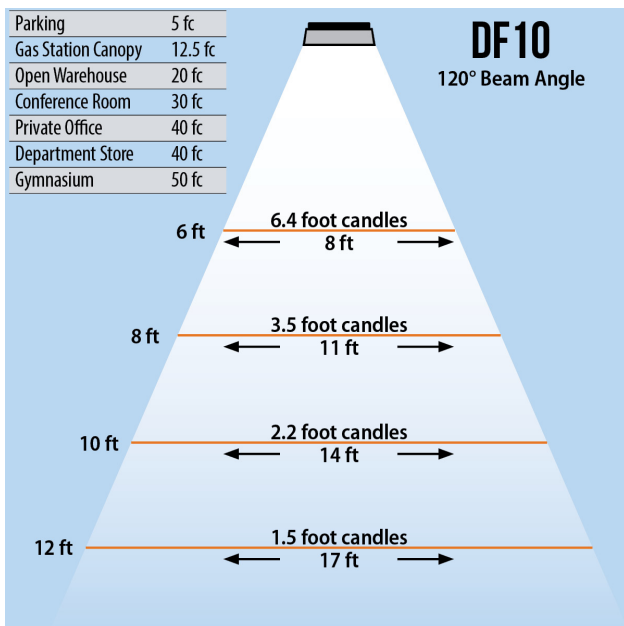

### ORDER CODE Example DF10-BRZ-10W120D6K

Fixture	Finish	Beam Angle	CCT
DF10 - Trunion	BRZ - Bronze	10W120D - 120°	6K - 6000K
DF10KM - Knuckle			3K - 3000K