

# DURAFLOOD 20

## LED FLOOD LIGHT (20 WATT)

120W PAR 38 Replacement




Trunnion Mount



Knuckle Mount

Lumens	1,800
CCT	3000-3500K, 6000-6500K
CRI	> 75
Beam Angle	120°
Operating Voltage	100 - 240 VAC
Power Consumption	20W
LED Source	Bridgelux
Lifespan	> 50,000 Hours
IP Grade	IP65
Body Construction	Aluminum & Toughened Glass
Dimensions	7.09" x 5.51" x 5.71"
Weight	2.65 lbs

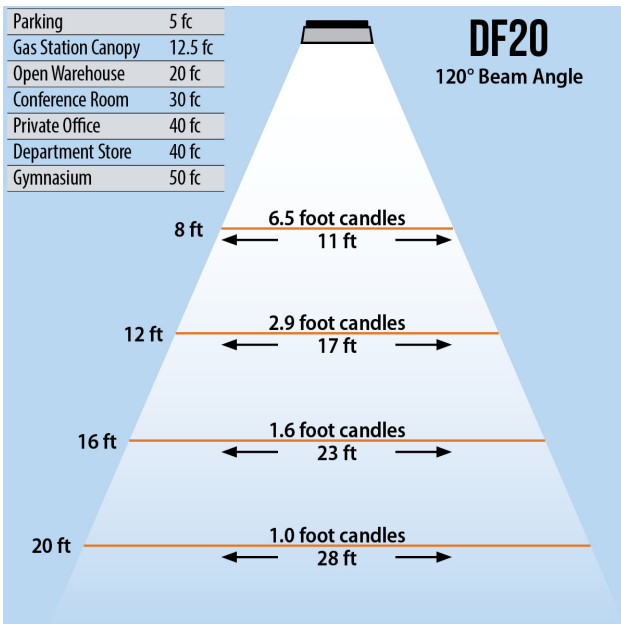

### ORDER CODE Example DF20-BRZ-20W120D6K

Fixture	Finish	Beam Angle	CCT
DF200 - Trunnion	BRZ - Bronze	20W120D - 120°	6K - 6000K
DF20KM - Knuckle			3K - 3000K

# DURAFLOOD 20

## LED FLOOD LIGHT (20 WATT)

120W PAR 38 Replacement




Lumens	1,800
CCT	3000-3500K, 6000-6500K
CRI	> 75
Beam Angle	120°
Operating Voltage	100 - 240 VAC
Power Consumption	20W
LED Source	Bridgelux
Lifespan	> 50,000 Hours
IP Grade	IP65
Body Construction	Aluminum & Toughened Glass
Dimensions	7.09" x 5.51" x 5.71"
Weight	2.65 lbs



Trunnion Mount



Knuckle Mount

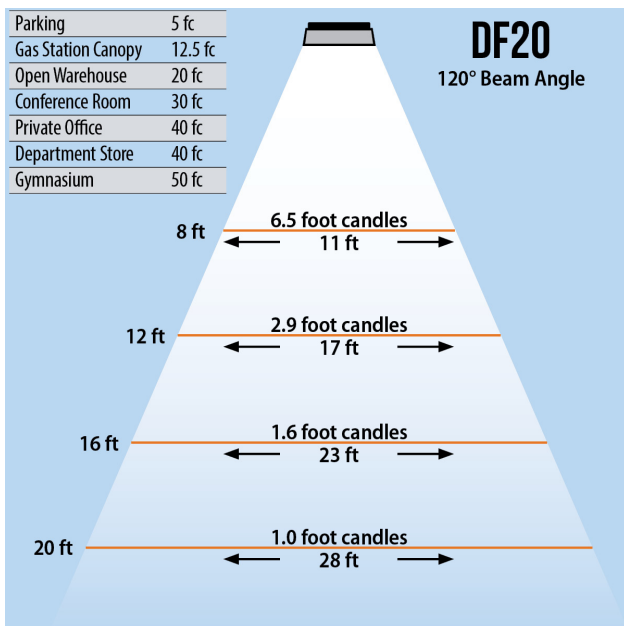

### ORDER CODE Example DF20-BRZ-20W120D6K

Fixture	Finish	Beam Angle	CCT
DF200 - Trunnion	BRZ - Bronze	20W120D - 120°	6K - 6000K
DF20KM - Knuckle			3K - 3000K