

## DURAFLOOD 240

## LED FLOOD LIGHT (240 WATT)

750 - 1000 MH Replacement




**480V AVAILABLE**



INVENTRONICS



		<b>480V</b>
Lumens	21,600	
CCT	6000-6500K	
CRI	> 75	
Beam Angle	120°	
Operating Voltage	100 - 277 VAC	180 - 528 VAC
Power Consumption	240W	
Driver	Mean Well	Inventronics
LED Source	Bridgelux	
Lifespan	> 50,000 Hours	
IP Grade	IP65	
Body Construction	Aluminum & Toughened Glass	
Dimensions	29.92" x 11.42" x 4.33"	
Weight	33.07 lbs	

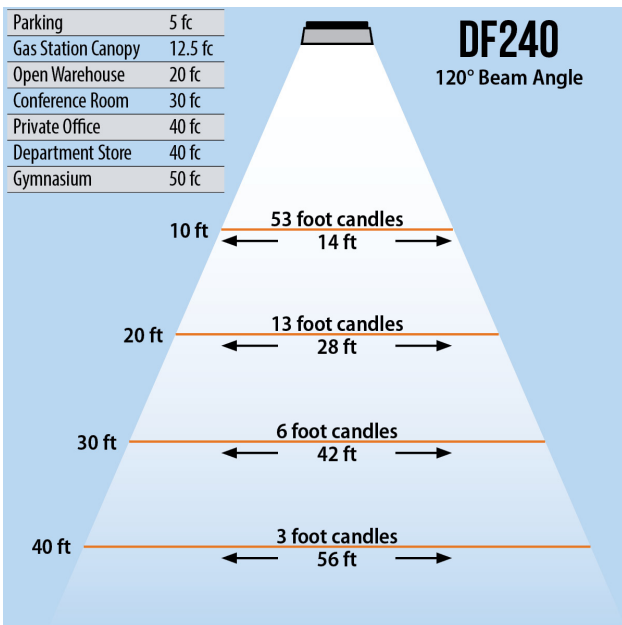

### ORDER CODE Example: DF240-BLK-240W120D6K

Fixture	Finish	Beam Angle	CCT	Voltage
DF240- Trunnion	BLK- Black	150W120-120°	6K- 6000K	___ - 240V
DF240S- Slipfitter				4V- 480V

Horizontal Slipfitter Option, **Black** SFK-BLK-DF240H  
 Vertical Slipfitter Option, **Black** SFK-BLK-DF240V

## DURAFLOOD 240



**480V AVAILABLE**

## LED FLOOD LIGHT (240 WATT)


750 - 1000 MH Replacement



INVENTRONICS



		<b>480V</b>
Lumens	21,600	
CCT	6000-6500K	
CRI	> 75	
Beam Angle	120°	
Operating Voltage	100 - 277 VAC	180 - 528 VAC
Power Consumption	240W	
Driver	Mean Well	Inventronics
LED Source	Bridgelux	
Lifespan	> 50,000 Hours	
IP Grade	IP65	
Body Construction	Aluminum & Toughened Glass	
Dimensions	29.92" x 11.42" x 4.33"	
Weight	33.07 lbs	

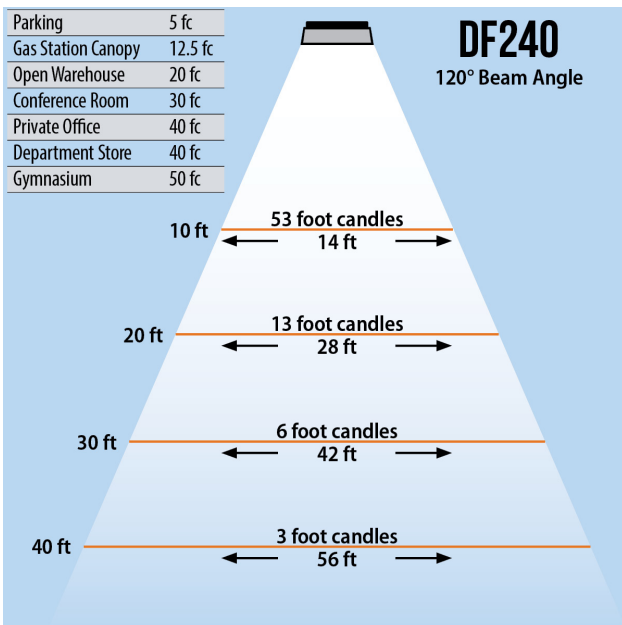

## ORDER CODE Example: DF240-BLK-240W120D6K

Fixture	Finish	Beam Angle	CCT	Voltage
DF240- Trunnion	BLK- Black	150W120-120°	6K- 6000K	___ - 240V
DF240S- Slipfitter				4V- 480V

Horizontal Slipfitter Option, **Black** SFK-BLK-DF240H  
 Vertical Slipfitter Option, **Black** SFK-BLK-DF240V