

**Description**

The E7RTAT is a compact and efficient recessed remodel Non-IC housing optimized and listed for EISA compliant tungsten-halogen, CFL and LED lamps as well as incandescent. Housing is suitable for residential or light commercial applications. For installation in non-insulated ceilings, if ceiling insulation is present it must be kept 3" from all sides of housing. Housing features Air-Tite code compliant construction. Use with a variety of trims and finishes to create different lighting effects or to match any decor. May be retrofit with compatible HALO LED lighting systems.

<b>Catalog #</b>		<b>Type</b>
<b>Project</b>		
<b>Comments</b>		<b>Date</b>
<b>Prepared by</b>		

**Specification Features**

**Housing**

- Single wall die-formed housing
- Housing features a precision rolled interlocking collar which maintains aperture geometry for greater assurance of installation results
- Integral Air-Tite gasket for code-required gasket between fixture and finished ceiling - seals aperture without need for additional caulk
- Shipped with socket overspray protector installed
- For installation from below the finished ceiling. Integral flange secures fixture against ceiling.
- Remodel Retention System - Speed Clamps
- Exclusive two integral speed clamps securely lock housing to ceiling, accommodating 3/8" to 2" ceiling materials

**Socket Plate**

- Rigid socket plate adjusts and locks without tools for various lamp sizes.
- Socket plate and bracket may be removed when using socket supporting trims.

**Includes:**

**Remodel Speed Clamps**

- (2) Exclusive integral speed clamps
- Speed clamp tabs securely lock to ceiling
- Speed clamps can be loosened for easy repositioning
- Speed clamps feature internal drive screws – a power screwdriver speeds installation
- Two-tier tabs adjust for 3/8" to 2" of various ceiling materials

**Attached-Arm Design**

- Attached arm gets into tight spaces
- Ease of installing through the ceiling aperture
- Smaller footprint for packing and distributor shelf space

**Hinged junction box w/ Slide-N-Side™**

- (4) 1/2" conduit pry-outs
- (2) Slide-N-Side™ Non-Metallic (NM) wire traps, allow wiring outside the box
- For 14-2, 14-3, 2-2, 12-3 U.S. and 14-2, 14-3, 12-2 Canadian
- Hinged door for easy access

**Quick Connect™ Wiring Tray**

- (3) Color coded push wire nuts in captive tray for one-handed connection
- Aids in speed & reliability
- Clear caps for wire connection visibility

**cULus Listed**

- Compact 10 in³ box volume
- Listed for maximum (6) No. 12 AWG or (8) No. 14 AWG 90° C splice conductors in box

**Remodel Flange**

- Die formed flange maintains precise whole circumference
- Integral flange secures fixture against the ceiling

**Air-Tite™ code compliant**

- Certified under ASTM E283
- Exclusive gasket seals aperture, frame & ceiling
- No additional caulk required

**Socket**

- Porcelain socket with nickel plated brass screw shell
- Snap-in springs secure socket to socket plate, and may be detached when using socket supporting trims

**Thermal Protector**

- Self resetting thermal protector deactivates fixture if overheating occurs due to improper lamping or misapplied insulation.

**Trims**

- Halo Fit-All concept offers multiple trim options in a variety of design styles, and functional beam distributions to control beam angle and lumen delivery in accommodating various lamp types including Halogen, CFL and LED

**Compliance**

- cULus Listed 1598 Luminaire
- cULus Listed Damp Location
- cULus Listed for Wet Location, covered ceiling, with select trims
- Air-Tite code compliant. Certified under ASTM E283; not exceeding 2.0 cfm (0.944 L/s) air leakage rate tested at a 1.57 psf (75 Pa) pressure differential
- RoHS compliant
- Options to meet Trade Agreements Act requirements




**E7RTAT**

**6" Non-IC, Air-Tite, Remodel Housing**

**E26 Screw base housing**

**Dimensions**

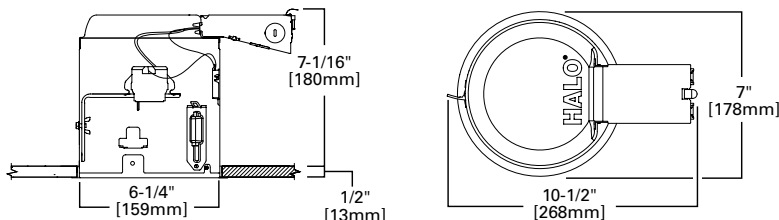

**Special Features**

- Hinged J-Box with Slide-N-Side™
- Quick Connect™ push wire nuts
- Air-Tite™ code compliant

## Ordering Information



Sample Number: E7RTAT 6110WB  
Order housing, trim and lamp (by others) separately for a complete luminaire.

### Domestic Preferences<sup>(1)</sup>

[Blank] = Standard  
TAA = Trade Agreements Act

### Housing

E7RTAT= 6" non-insulated ceiling, airtight recessed housing, remodel, 120V

Trims		
 <p><b>Reflectors</b></p> <p><b>30 Reflector, Self-flange</b> OD: 7-1/4" [184mm] 30HAT=Haze Reflector, White Trim 30RGAT=Residential Gold Reflector, White Trim 30CAT=Clear Specular Reflector, White Trim</p> <p><b>30SBAT Reflector, Self-flange</b> OD: 7-1/4" [184mm] 30SBAT=Black Specular Reflector, Trim</p> <p><b>405 Specular Full Cone Reflector</b> OD: 7-1/4" [184mm] 405SC=Clear Specular Reflector, White Trim</p> <p><b>426 Reflector Cone</b> OD: 7-1/4" [184mm] 426=Clear Specular Reflector Cone, White Trim 426MB=Black Specular Reflector Cone, White Trim 426H=Haze Reflector Cone, White Trim 426SN=Satin Nickel Reflector Cone and Trim 426TBZ=Tuscan Bronze Reflector Cone and Trim</p> <p><b>429 Dayform White Cone</b> OD: 7-1/4" [184mm] 429P=White Reflector and Trim</p> <p><b>4051 White Full Cone Reflector, Self-flange</b> OD: 7-1/4" [184mm] 4051P=White Reflector and Trim</p> <p><b>4261 White Reflector Cone, Self-flange</b> OD: 7-1/4" [184mm] 4261P=White Reflector and Trim</p> <p><b>6106 Straight Reflector Cone, Self-flange</b> OD: 7-3/4" [197mm] 6106SC=Specular Reflector, Trim</p> <p><b>6107 Tapered Reflector, Self-flange</b> OD: 7-3/4" [197mm] 6107SC=Specular Reflector, White Trim</p> <p><b>6120 Full Cone Reflector, Self-flange</b> OD: 7-3/4" [197mm] 6120WH=White Reflector and Trim 6120SN=Satin Nickel Reflector and Trim 6120TBZ=Tuscan Bronze Reflector and Trim</p> <p><b>6121 Shallow Full Cone Reflector, Self-flange</b> OD: 7-3/4" [197mm] 6121WH=White Reflector and Trim</p> <p><b>Baffles</b></p> <p><b>30 Baffle, Self-flange</b> OD: 7-1/4" [184mm] 30WAT=White Baffle, Reflector and Trim 30WATH=White Baffle, Clear Reflector and White Trim 30PAT=Black Baffle, Clear Reflector and White Trim 30SNAT=Satin Nickel Baffle, Reflector and Trim 30TBZAT=Tuscan Bronze Baffle, Reflector and Trim</p> <p><b>310 Coilex® Baffle</b> OD: 7-1/4" [184mm] 310W=White Coilex Baffle and Trim 310P=Black Coilex Baffle, White Trim 310SN=Black Coilex Baffle, Satin Nickel Trim 310TBZ=Black Coilex Baffle, Tuscan Bronze Trim</p>	 <p><b>312 Coilex® Baffle</b> OD: 7-1/4" [184mm] 312W=White Coilex Baffle and Trim 312P=Black Coilex Baffle, White Trim</p> <p><b>353 Metal Baffle</b> OD: 7-1/4" [184mm] 353SN=Satin Nickel Baffle and Trim 353TBZ=Tuscan Bronze Baffle and Trim</p> <p><b>410 Coilex Straight Plastic Baffle</b> OD: 7-1/4" [184mm] 410W=White Baffle, White Metal Trim 410P=Black Baffle, White Metal Trim</p> <p><b>6100 Tapered Metal Baffle with (2) Trim Rings</b> OD: 7-1/8" [181mm] 6100WB=White Baffle, Narrow and Wide White Trims (included) 6100BB=Black Baffle, Narrow and Wide White Trims (included)</p> <p><b>6101 Straight Metal Baffle with (2) Trim Rings</b> OD: 7-1/8" [181mm] 6101WB=White Baffle, Narrow and Wide White Trims (included) 6101BB=Black Baffle, Narrow and Wide White Trims (included)</p> <p><b>6102 Tapered Metal Baffle, Self-flange</b> OD: 7-3/4" [197mm] 6102WB=White Baffle and Trim 6102BB=Black Baffle, White Trim</p> <p><b>6103 Straight Metal Baffle, Self-flange</b> OD: 7-3/4" [197mm] 6103WB=White Baffle and Trim 6103BB=Black Baffle, White Trim</p> <p><b>6108 Coilex® Straight Plastic Baffle, Self-flange</b> OD: 7-3/4" [197mm] 6108WB=White Plastic Straight Coilex Baffle, White Trim 6108BB=Black Plastic Straight Coilex Baffle, White Trim 6108BKBB=Black Plastic Straight Coilex Baffle, Black Trim</p> <p><b>6109 Coilex® Tapered Baffle, Self-flange</b> OD: 7-3/4" [197mm] 6109WB=White Tapered Coilex Baffle, White Trim 6109BB=Black Tapered Coilex Baffle, White Trim 6109BKBB=Black Tapered Coilex Baffle, Black Trim</p> <p><b>6110 Pertex Baffle, Self-flange</b> OD: 7-3/4" [197mm] 6110WB=White Pertex Baffle and Trim 6110BB=Black Pertex Baffle, White Trim 6110BKBB=Black Pertex Baffle and Trim</p> <p><b>6125 Full Cone Baffle, Self-flange</b> OD: 7-3/4" [197mm] 6125WB=White Baffle and Trim 6125BB=Black Baffle, White Trim 6125BKBB=Black Baffle and Trim</p> <p><b>6126 Shallow Full Cone Baffle, Self-flange</b> OD: 7-3/4" [197mm] 6126WB=White Baffle and Trim 6126BB=Black Baffle, White Trim</p>	<p><b>Adjustable - Eyeballs &amp; Gimbals</b></p> <p><b>74 PAR30 Eyeball 30° Tilt, Self-flange</b> OD: 8" [203mm] 74P=White Eyeball and Trim</p> <p><b>76 PAR38 Gimbal 30° Tilt, Self-flange</b> OD: 8" [203mm] 76P=White Gimbal and Trim</p> <p><b>78 BR/PAR30 Eyeball 30° Tilt, Self-flange</b> OD: 8" [203mm] 78P=White Eyeball and Trim 78PAT=White Eyeball and Trim, Air-Tite 78SN=Satin Nickel Eyeball and Trim 78TBZ=Tuscan Bronze Eyeball and Trim</p> <p><b>376 PAR30 Regressed Gimbal 30° Tilt, Self-flange</b> OD: 7-1/4" [184mm] 376W=White Baffle and Trim 376P=Black Baffle and White Trim</p> <p><b>419 Regressed Eyeball with Splay 25° Tilt</b> OD: 7-1/4" [184mm] 419P=White Eyeball and Splay, White Trim</p> <p><b>420 BR/PAR30 Regressed Eyeball 30° Tilt, Self-flange</b> OD: 7-1/4" [184mm] 420W=White Eyeball, Baffle and Trim 420P=White Eyeball, Black Baffle, White Trim</p> <p><b>478 PAR38 Adjustable Regressed Gimbal with Splay 25° Tilt, Self-flange</b> OD: 7-1/4" [184mm] 478P=White Splay and Trim</p> <p><b>6130 BR/PAR30 Eyeball 35° Tilt, Self-flange</b> OD: 7-3/4" [197mm] 6130WH=White Eyeball and Self-flange</p> <p><b>6170 PAR38 Gimbal 25° Tilt, Self-flange</b> OD: 7-3/4" [197mm] 6170WH=White Gimbal and Self-flange 6170BK=Black Gimbal and Self-flange 6170SN=Satin Nickel Gimbal and Self-flange 6170TBZ=Tuscan Bronze Gimbal and Self-flange</p> <p><b>6215 PAR30 Double Gimbal 35°-50° Tilt, Self-flange</b> OD: 7-3/4" [197mm] 6215WH=White Gimbal and Self-flange 6215BK=Black Gimbal and Self-flange 6215SN=Satin Nickel Gimbal and Self-flange 6215TBZ=Tuscan Bronze Gimbal and Self-flange</p> <p><b>6222 Regressed PAR30 Adjustable 45° Tilt, Self-flange</b> OD: 7-3/4" [197mm] 6222WB=White Regressed Gimbal and Trim 6222BB=Black Regressed Gimbal and Trim 6222SC=Specular Clear Regressed Gimbal and Trim 6222H=Haze Regressed Gimbal and Trim</p>

Notes: (1) Only product configurations with this designated prefix are built to be compliant with the Trade Agreements Act of 1979 (TAA). Please refer to [DOMESTIC.PREFERENCES](http://DOMESTIC.PREFERENCES) website for more information. Components shipped separately may be separately analyzed under domestic preference requirements. Accessories sold separately will be separately analyzed under domestic preference requirements. Consult factory for further information.

## Ordering Information

Sample Number: E7RTAT 6110WB  
Order housing, trim and lamp (by others) separately for a complete luminaire.














 











### Domestic Preferences<sup>(1)</sup>

[Blank] = Standard  
TAA = Trade Agreements Act

### Housing

E7RTAT= 6" insulated ceiling, airtight recessed housing, remodel, 120V

### Trims

Lenses & Wet Location Showerlights		6230 Squirrel Frost Glass Lens, Metal Trim - Showerlight		Low Voltage	
	<b>70 Albalite Lens</b> OD: 8" [203mm] 70P=Albalite Glass Lens, White Plastic Trim 70PS=Albalite Glass Lens, White Plastic Trim, Showerlight, Air-Tite		OD: 7-1/4" [183mm] 6230AH=Frost Glass Lens, Aluminum Haze Squirrel Trim 6230PN=Frost Glass Lens, Polished Nickel Squirrel Trim 6230SN=Frost Glass Lens, Satin Nickel Squirrel Trim 6230TBZ=Frost Glass Lens, Tuscan Bronze Squirrel Trim		<b>1475 Low Voltage Adjustable Accent 30° Tilt</b> OD: 7-1/4" [183mm] 1475W=White Baffle and Trim 1475P=Black Baffle, White Trim
	<b>71 Drop Opal Glass Lens</b> OD: 8" [203mm] 71P=Drop Opal Glass Lens, White Plastic Trim 71PS=Drop Opal Glass Lens, White Plastic Trim, Showerlight, Air-Tite		<b>6255 Soft Square, Frost Curve Glass Lens, Self-flange - Showerlight</b> OD: 7-1/4" [183mm] 6255WH=Frost Curve Glass Lens with Reflector, White Plastic Trim 6255SN=Frost Curve Glass Lens with Reflector, Satin Nickel Plastic Trim 6255TBZ=Frost Curve Glass Lens with Reflector, Tuscan Bronze Plastic Trim		<b>1479 Low Voltage Pinhole Trim</b> OD: 8" [203mm] 1479W=White Baffle and Trim 1479P=Black Baffle, White Trim
	<b>73 Fresnel Glass Lens</b> OD: 8" [203mm] 73P=Fresnel Glass Lens, White Plastic Trim 73PS=Fresnel Glass Lens, White Plastic Trim, Showerlight, Air-Tite		<b>Open, Splay &amp; Wall Wash</b>		
	<b>170 Albalite Lens with Reflector</b> OD: 8" [203mm] 170P=Frosted Albalite Glass Lens, White Trim 170PS=Frosted Albalite Glass Lens, White Plastic Trim, Showerlight, Air-Tite		<b>79 Pinhole Trim</b> OD: 8" [203mm] 79=Pinhole White Trim		
	<b>171 Drop Opal Lens with Reflector</b> OD: 8" [203mm] 171P=Drop Opal Glass Lens, White Trim 171PS=Drop Opal Glass Lens, White Plastic Trim, Showerlight, Air-Tite		<b>300 Open Trim with Fixed Socket Bracket, Self-flange</b> OD: 7-1/4" [183mm] 300P=Self-flange with White Open Trim 300SN=Self-flange with Satin Nickel Open Trim 300TBZ=Self-flange with Tuscan Bronze Open Trim		
	<b>172 Dome Lens with Reflector</b> OD: 7-3/4" [197mm] 172PS=Frosted Glass Dome, White Plastic Trim 172SNS=Frosted Glass Dome, Satin Nickel Plastic Trim 172TBZ=Frosted Glass Dome, Tuscan Bronze Plastic Trim		<b>301 Open Trim</b> OD: 7-1/4" [183mm] 301P=White Open Trim 301SN=Satin Nickel Open Trim 301TBZ=Tuscan Bronze Open Trim		
	<b>173 Fresnel Lens with Reflector</b> OD: 8" [203mm] 173P=Fresnel Glass Lens, White Trim 173PS=Fresnel Glass Lens, White Plastic Trim, Showerlight, Air-Tite		<b>328 White Splay Trim</b> OD: 7-3/4" [197mm] 328P=White Splay Trim		
	<b>6145 Open Wet Location, Shallow Reflector, Self-flange*</b> OD: 7-3/4" [197mm] 6145WH=White Reflector and Trim 6145SN=Satin Nickel Reflector and Trim 6145TBZ=Tuscan Bronze Reflector and Trim		<b>401 Open Trim</b> OD: 8" [203mm] 401P=White Open Trim 401AL=Satin Aluminum Open Trim		
	<b>6146 Open Wet Location, Full Reflector, Self-flange*</b> OD: 7-3/4" [197mm] 6146WH=White Reflector and Trim 6146SN=Satin Nickel Reflector and Trim 6146TBZ=Tuscan Bronze Reflector and Trim		<b>428 White Splay Trim</b> OD: 7-3/4" [197mm] 428P=White Splay Trim		
	<b>6150 Frost Dome Glass Lens, Self-flange</b> OD: 7-3/4" [197mm] 6150WH=Frost Dome Glass Lens with Reflector, White Plastic Trim 6150SN=Frost Dome Glass Lens with Reflector, Satin Nickel Plastic Trim 6150TBZ=Frost Dome Glass Lens with Reflector, Tuscan Bronze Plastic Trim		<b>303 Wall Wash with Scoop</b> OD: 8" [203mm] 303P=White Wall Wash Scoop, White Trim		
	<b>6160 Drop Opal Plastic Lens, Self-flange</b> OD: 7-3/4" [197mm] 6160WH=Drop Opal Plastic Lens, White Plastic Trim		<b>424 Open Wall Wash / Reflector Downlight</b> OD: 7-1/4" [183mm] 424P=Open Wall Wash and Downlight, White Trim		
			<b>425 Wall Wash with Coilex Baffle and Scoop Reflector</b> OD: 7-1/4" [183mm] 425W=White Coilex Baffle, White Trim 425P=Black Coilex Baffle, White Trim		
			<b>430 Wall Wash with Baffle &amp; Full Reflector</b> OD: 7-1/4" [183mm] 430W=White Baffle, with Upper Reflector, White Trim 430P=Black Baffle, with Upper Reflector, White Trim		

Notes: (1) Only product configurations with this designated prefix are built to be compliant with the Trade Agreements Act of 1979 (TAA). Please refer to [DOMESTIC PREFERENCES](#) website for more information. Components shipped separately may be separately analyzed under domestic preference requirements. Accessories sold separately will be separately analyzed under domestic preference requirements. Consult factory for further information.

\*Outdoor rated lamp only (purchase separately)